


# Spherical roller bearings, cylindrical and tapered bore



Principal dimensions			Basic load ratings		Fatigue load limit $P_u$	Speed ratings		Mass	Designation
d	D	B	dynamic	static		Reference speed	Limiting speed		
mm			kN	$C_0$	kN	r/min		kg	* - SKF Explorer bearing
80	140	40	236	270	29	-	1200	2,40	BS2-2216-2CS/VT143 *

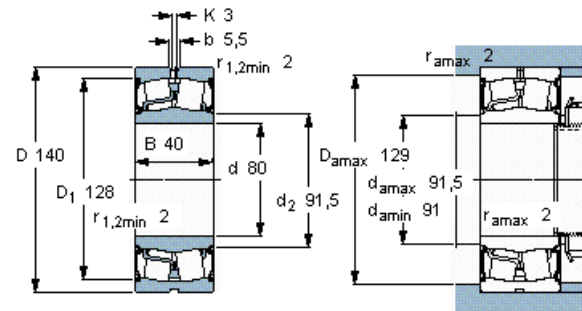

### Calculation factors

- e 0,22
- $Y_1$  3
- $Y_2$  4,6
- $Y_0$  2,8