



Angular contact ball bearings, double row

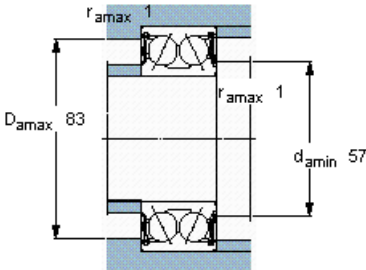

Principal dimensions			Basic load ratings		Fatigue load limit P_u	Speed ratings		Mass	Designation
d	D	B	dynamic	static		Reference speed	Limiting speed		
mm			kN	C_0	kN	r/min		kg	-
50	90	30,2	51	39	1,66	-	4800	0,65	3210 A-2RS1TN9/MT33 *

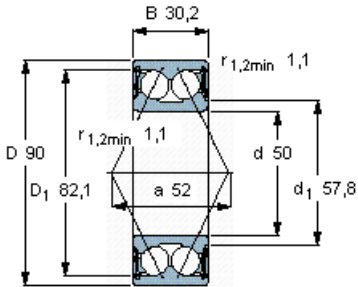

Calculation factors

k_r 0,06
 e 0,8
 X 0,63
 Y_1 0,78
 Y_2 1,24
 Y_0 0,66