
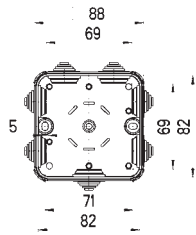


HP 90

90 x 90 x 45 mm,
internal dimension: 82 x 82 x 38 mm

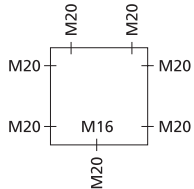

Description

Order No.

Packing Qty

Junction box acc. DIN EN 60670 (VDE 0606), $U_i=400V$,
7 recessed stepped nipples, seal range 5 - 16 mm, for terminals up to 4 mm²

IP55

4²

IK07



400V
AC





HP 90-L
grey, without terminals

325 990 01

40/1

HP 100

113 x 113 x 58 mm
internal dimension: 103.5 x 103.5 x 32 mm

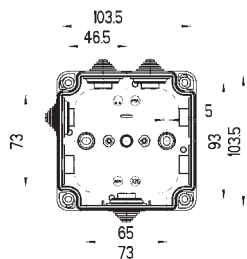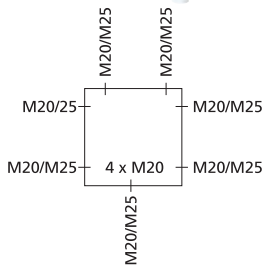

Junction box acc. DIN EN 60670 (VDE 0606), $U_i=690V$,
7 recessed stepped nipples, seal range 5 - 21 mm, for terminals up to 10 mm²

IP55

10²

IK07



690V



HP 100-L
grey, without terminals

326 900 01

20/1