



order number : 740


## Receptacle

with high heat resistant contact carriers and nickel plated contacts

32A7P 6H400V panel mounted receptacle

IP44

with high heat resistant contact carriers and nickel plated contacts

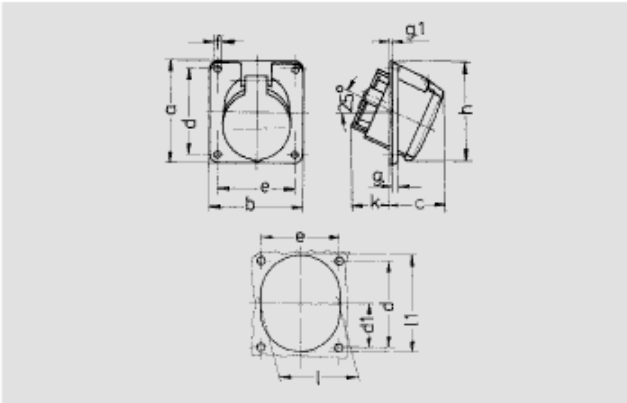

Zeichnung	Amp.	16	32
1 MB 256	Pole	7	7
Maße in mm	a	100	100
	b	92	92
	c	48	51
	d	85	85
	d1	42,5	45,5
	e	77	77
	f	5,1	5,1
	g	6	6
	g.1	2	2
	h	100	102
	k	39	58
	l	78	78
Leiterquerschnitt	I1	78	87
von bis mm <sup>2</sup>		1,5	2,5
		—4	—10

 Article-group : **1044**

voltages : 400V

rated current : 32A

pole : 7 pole

IP protection types : IP44

position of ground contact : 6h

packing unit : 0010

flange, fixing hole : FL 100x92mm BL 85x77mm N20°







pilot contact (63A-125A) : without pilot-contact

contact carriers : reliable contact frame

contact technique : screw contact

weight : 300 g

### PART NUMBERS

V	110V	230V	400V	500V	>50-500V	
Hz	50,60	50,60	50,60	50,60	100-300	300-500
colour						
amp.						
<b>16 A</b>	7	737	738	1045		
<b>32 A</b>	7	739	<b>740</b>	1050		