


Deep groove ball bearings, single row, unsealed

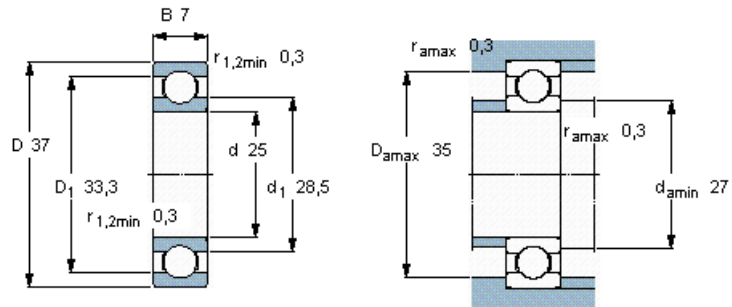

Principal dimensions			Basic load ratings		Fatigue load limit P_u	Speed ratings		Mass	Designation
d	D	B	dynamic	static		Reference speed	Limiting speed		
mm			kN		kN	r/min		kg	-
25	37	7	4,36	2,6	0,125	38000	24000	0,022	61805



Calculation factors

k_r 0,015
 f_0 14