

# Female x Female Straight Coupler Threaded Fitting




## Description

For use with the body and nut in order to form a complete Legris compression fitting.

Recommended for connection to thermoplastic, brass or hardened copper. Ensures optimum sealing of installation.

## Technical Specifications

Maximum Working Pressure	250 bar 25 Mpa 3626 psi
Working temperature	-40 to 150 °C -40 to 302 °F 233 to 423 °K
Body	BRASS

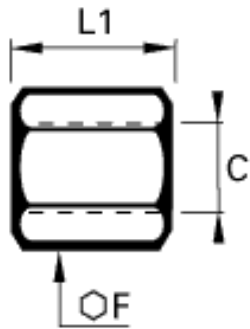

## Dimensions

C	F (MM)	L (MM)	Weight (kg)
G1/4	17	24	0.26