


# ST50 500W SOLDERING IRON

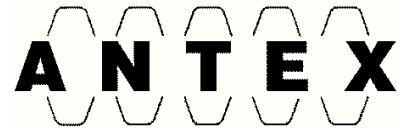


## DATA SHEET

**769-3135**



### **SPECIFICATIONS ST50 (STRAIGHT) 500WATT SOLDERING IRON**

NOMINAL POWER (W)	500
STANDARD VOLTAGE	230
NOMINAL TIP TEMP (°C)	470
FITTED BIT (D.F.)	1 1/4" (32mm)
CABLE LENGTH (m)	2.0
CABLE TYPE	Rubber with European plug
HANDLE MATERIAL	Wood
COUNTRY OF ORIGIN	U.K.
WEIGHT gms. (approx.)	1650
DIMENSIONS (approx.)	A: (bit) 80 mm. B: (handle & element) 330mm

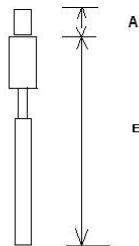

#### **TYPICAL APPLICATIONS:**

Heavy duty tasks. Features large bit with rapid heat replacement. Extensively used for heavy maintenance work including electronic motors with high temperature alloys, large metal boxes, radiator manufacture and for joining busbars.