


# ZRB18AR61C106ME01#

"#" indicates a package specification code.



< List of part numbers with package codes >  
ZRB18AR61C106ME01L

## Shape

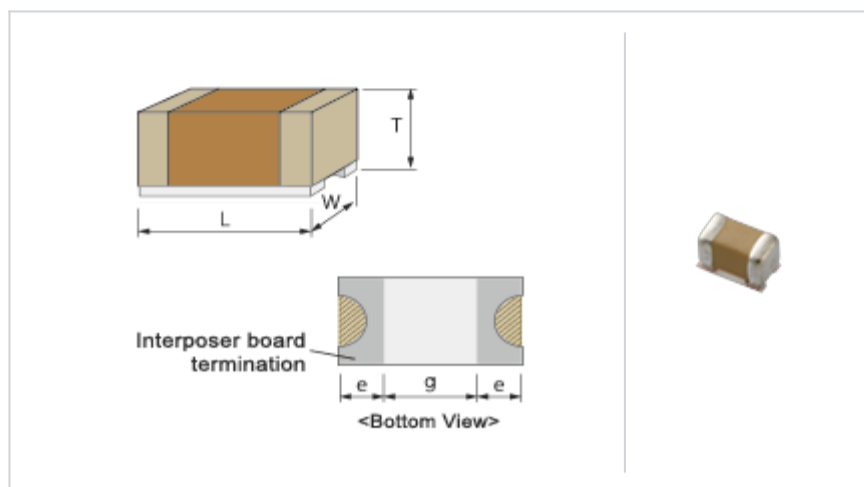

L size	1.6 ± 0.2mm
W size	0.8 ± 0.2mm
T size	1.0 ± 0.2mm
External terminal width e	0.2 to 0.65mm
Distance between external terminals g	0.6mm min.
Size code in inch(mm)	0603 (1608)

## References

Packaging	Specifications	Minimum quantity
L	180mm Embossed taping	3000

Mass (typ.)	
1 piece	9.9mg

## Specifications

Capacitance	10μF ± 20%
Rated voltage	16Vdc
Temperature characteristics (complied standard)	X5R(EIA)
Capacitance change rate	± 15.0%
Temperature range of temperature characteristics	-55 to 85
Operating temperature range	-55 to 85

### ⚠ Attention

- 1.This datasheet is downloaded from the website of Murata Manufacturing Co., Ltd. Therefore, it ' s specifications are subject to change or our products in it may be discontinued without advance notice. Please check with our sales representatives or product engineers before ordering.
- 2.This datasheet has only typical specifications because there is no space for detailed specifications. Therefore, please review our product specifications or consult the approval sheet for product specifications before ordering.