



Double hexagon Inch, 7800DZ

 

Sockets Double Hexagon Inch
DIN 3124/ISO 2725.

1/2" 12.5 DIN 3120/ISO 1174.

Finish: nickel and chrome-plated, fine-polished.

Material: CHROME-EXTRA.

With Dynamic-Drive-Profile.

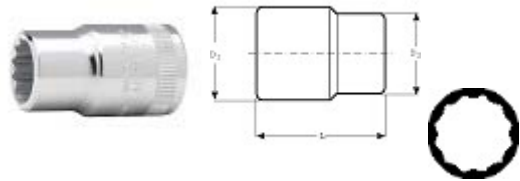

L
mm

D1
mm

D2
mm

| | | | | L mm | D1 mm | D2 mm |
|---------------|---------|---|--------|---------|----------|----------|
| 7800DZ-1.1/16 | 1097578 | 1 | 1 1/16 | 44 | 36.6 | 29.0 142 |
| 7800DZ-1.1/8 | 1097585 | 1 | 1 1/8 | 46 | 38.6 | 29.0 157 |
| 7800DZ-1.3/16 | 1097592 | 1 | 1 3/16 | 47 | 40.4 | 29.0 178 |
| 7800DZ-1.1/4 | 1097608 | 1 | 1 1/4 | 47 | 42.3 | 30.5 185 |