


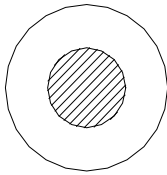

Product Name:	UL1431 26AWG
Product Discription:	UL1431 26AWG
Specification No.:	
Customer's Name:	

Description				
Rated Voltage:		600V		
Rated Temperature:		105℃		
Reference Standard:		UL758,UL1581		
Cross Section				
				
Marking				
AWM XLPVC 1431 26AWG 105℃ 600V Horizontal flam AWM XLPVC 105℃ 600V I A FT2 E214859 YANG TAI				
Applications				
For internal wiring of electronic and electrical equipment				
Revisions				
Version	Description	Drawn by	Approved by	Date
0	New document issue	Huang	Jason	14/04/2015
Construction				
Conductor		Stranded Tinned Copper		
Size(AWG)		26		
Construction(±0.008mm)		7/0.16		
Stranded Dia.(mm)Ref.		0.48		
Insulation Material		XLPVC		
Insulation Color		ANY COLOR		
Ave Thickness(mm)		0.76		
Insulation Dia.(±0.10mm)		2.00		
Remark: 8740034 Red 8740043 Blue 8740056 Grey 8740065 Violet 8740037 Black 8740046 White 8740059 Yellow 8740030 Brown 8740040 Green 8740052 Orange				
Characteristics				Customer Approve
Test Item			Standard Value	
Test Material			XLPVC(ROHS)	
Insulation resistance(20℃ MΩ*m			1000	
Vol. Tesr(AC.V.60S) (V)			2000	
Flammability Test			Horizontal flame	
Max.DC Resistance(20℃ Ω/km)			150(MAX)	
			Signature:	
			Date:	