


3-Wire *microfast*® Cordsets, Standard Duty

- Right Angle Female Connectors
- NEMA 1, 3, 4, 6P and IEC IP 67 Protection
- 250 V, 4.0 A



Housing Style	Part Number	Cable	Features	Pinout
	WKB 3T-*	AWM PVC Yellow 3x22 AWG 105°C 5.2 mm OD Cable #RF50531- [†] M [†]	<i>flexlife</i> ®	<ol style="list-style-type: none"> 1. GN 2. RD/BK 3. RD/WH
	WKB 3T-*/S90	AWM PUR Yellow 3x18 AWG 80°C 5.7 mm OD Cable #RF50547- [†] M [†]	<i>Cut/Abrasion Immune</i>	
	WKB 3T-*/S105	AWM PVC Yellow 3x22 AWG 105°C 5.7 mm OD Cable #RF50535- [†] M [†]	<i>Braided Copper Shield</i>	
	WKB 3T-*/S749	AWM PVC Yellow 2x22 AWG 105°C 5.2 mm OD Cable #RF50650- [†] M [†]	<i>3-pin with 2 conductors</i>	<ol style="list-style-type: none"> 1. N/C 2. BK 3. WH
	WKB 3T-*/S1507	AWM TPE Grey 3x20 AWG 105°C 5.7 mm OD Cable #RF50940- [†] M [†]	<i>Flexlife-10, High Flex - Over 10 Million Cycles</i>	<ol style="list-style-type: none"> 1. BK 2. BN 3. BU
	WKB 3T-*/X0R	AWM PVC Yellow 3x18 AWG 80°C 250°C short term 5.7 mm OD Cable #RF04159- [†] M [†]	<i>Weld Flash Immune, High Temp Immune</i>	<ol style="list-style-type: none"> 1. GN 2. RD 3. RD/WH

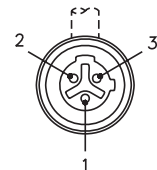

* Length in meters. Standard cable lengths are 2, 4, 6, 8 and 10 meters. Consult factory for other lengths.

** Standard coupling nut material is nickel plated brass "WKB .."; "WKBV .." indicates 316 stainless steel.

[†] See Section N for *reelfast*® cable information.