


Verbatim LED GU10 6W 2700K 400lm 2700K Warm White 420 LM DIM




- GU10 Socket
- 220-240V
- 40,000 hours Lifetime
- Dimmable
- 89% Energy Saving
- Luminous Flux: 420 lm
- Equivalent to 57W incandescent bulb

Product Number	52312
General Data	
Lamp Socket	GU10
Electric Data	
Wattage (W)	6.0
Wattage Equivalent (W)	57
Voltage (V)	220-240
Dimmable	yes
Power Factor	≥0.7
Operating Frequency (Hz)	50/60
Geometric Data	
Length (mm)	56
Diameter (in mm)	50
Weight (g)	55
Photometric Data	
Luminous Flux (lm)	420
Luminous Flux 90° Cone (lm)	400
CRI	80
CCT (K)	2700
Luminous Intensity (cd)	1000
Beam Angle (°)	35
Luminous Efficacy (lm/W)	70
Lifetime (hrs)	40,000
Switching Cycle	100,000

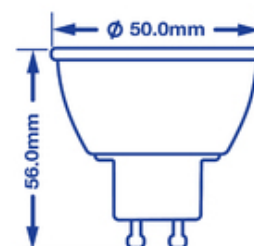


28/11/2014

Photometric Diagrams

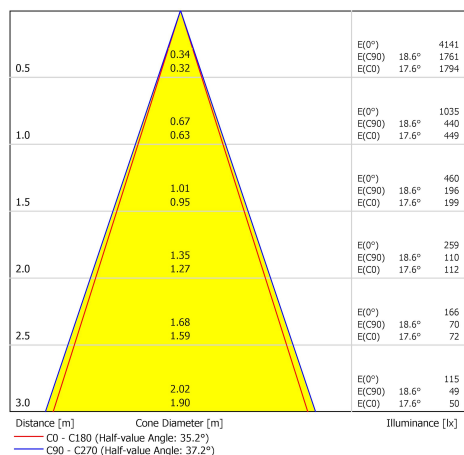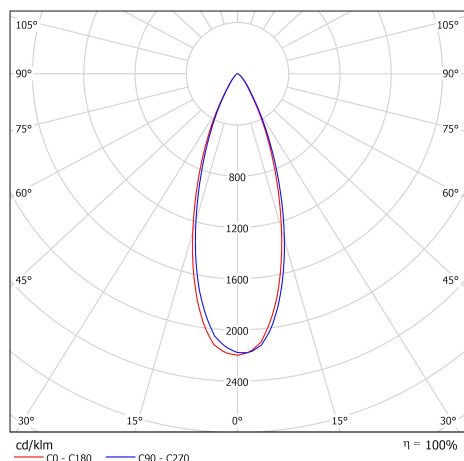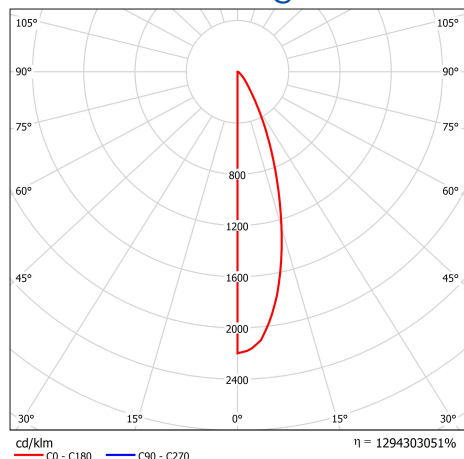

Energy Rating

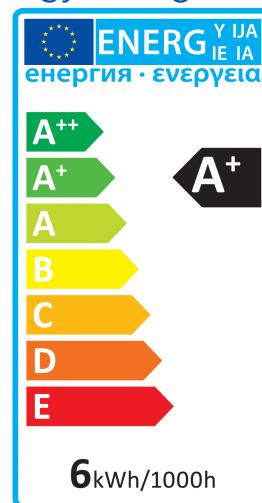

Technical Packaging Details

Barcode
 023942523123

EAN 128
 (02)00023942523123(37)10(91)814

EAN 14
 50023942523128

Pack Dimensions(HxWxL)
 H67 *W51*L51mm (mm)

MOQ
 10

Carton Dimensions (HxWxL)
 H97*W125 *L285mm (mm)

Cartons/Pallet
 171

Layers/Pallet
 9

Units/Pallet
 1710

28/11/2014