



MASTER LEDtube Value

MASTER LEDtube VLE HF 1200mm 16.5W840 T8 C

The Philips MASTER LEDtube integrates a LED light source into a traditional fluorescent form factor. Its unique design creates a perfectly uniform visual appearance which cannot be distinguished from traditional fluorescent. This product is the ideal solution for up lighting in general lighting applications.

Product data

• General Characteristics

Main Application	Industrial
Cap-Base	G13
Rated Lifetime	40000 hr
Nominal Lifetime hours	40000
B50L70	40000

• Light Technical Characteristics

Colour Code	840
Beam Angle	160 D
Correlated Colour Temperature	4000 K
Colour rendering index	83
Rated Luminous Flux	1600 Lm
LLMF - end nominal lifetime	70 %
Colour consistency	<6
Rated Beam Angle	160 D

• Electrical Characteristics

Wattage	16.5 W
Voltage	220-240 V
Line Frequency	50/60 Hz
Power Factor	0.9 (min) -
Dimmable	No
Rated Wattage	16.5 W
Starting Time	0.5 (max) s
Lamp voltage	100-240 V
Warm-up Time to 60% Light Outp	instant full light
Energy saving product	Yes

Suitable for accent lighting No

• Temperature Characteristics

T-case maximum	55 (max) C
Operating temperature	-20 (min), 45 (max) C
T-Storage	-40 (min), 65 (max) C

• Environmental characteristics

Energy Efficiency Label (EEL) A

• Measuring Conditions

Switching cycle 50000X

• Product Dimensions

Length A1	1198.0 mm
Fixing Hole Distance	1205.0 mm
A2 Length	
Length A3	1212.0 mm
Mounting hole diameter	25.68 mm
Circular outline dimension	27.8 mm

• Approval & Application Chars

VDE marking	No
CE marking	Yes
UL certificate	No
RoHS compliance	Yes



PHILIPS

MASTER LEDtube Value


KEMA Keur certificate Yes

Pieces per pack 1
 Packing configuration 10
 Packs per outerbox 10
 Bar code on pack - EAN1 8718291728856
 Bar code on outerbox - EAN3 8718291728863
 Logistic code(s) - 12NC 929000284402
 Net weight per piece 0.270 kg

• Product Data


Order code 728856 00
 Full product code 871829172885600
 Full product name MASTER LEDtube VLE HF 1200mm 16.5W840 T8 C
 Order product name MST LEDtube VLE HF 1200mm 16.5W840 T8 C

Dimensional drawing

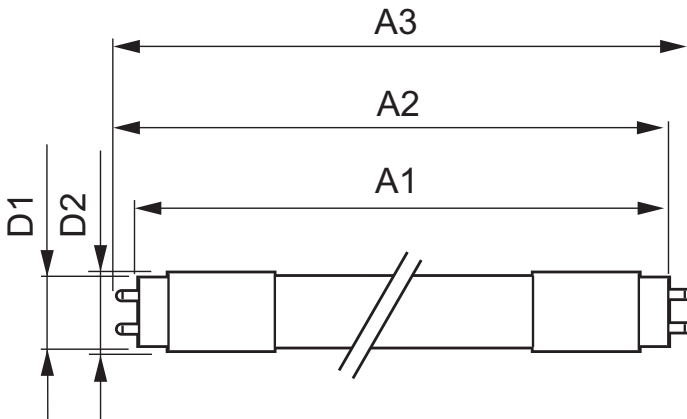

MASTER LEDtube VLE HF 1200mm 16.5W840 T8 C

Product	A (Norm)	A1 (Norm)	A2 (Norm)	A3 (Norm)	B (Min)	B (Norm)	B (Max)	D (Min)	D (Norm)	D (Max)	D1 (Norm)	D2 (Norm)
LEDtube VALUE HF 1200mm 16.5W/840 T8 C	-	1198.0	1205.0	1212.0	-	-	-	-	-	-	25.68	27.8

 

G13



© 2014 Koninklijke Philips N.V. (Royal Philips)
 All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips N.V. (Royal Philips) or their respective owners.

www.philips.com/lighting

2014, July 27
 data subject to change