

RIO Reflector with 90W CM City Lamp

Kit including ballast is available

Product codes: RIO Reflector: RFLCMCE40
Lamp: 00952

Lamp Performance Data

Lamp Type	Ceramic metal halide
Light Output (Lumens & 100 hours)	10450
Lumens Per Watt	116
Rated Life (Hrs @ 10 Hr/Start)	30000
Correlated Colour Temperature (K)	2800
Chromaticity (CIE - X Y)	455, 405
Colour Rendering Index (CRI)	70
Burning Position	Horizontal
Dimming	Capable

Electrical Data


Lamp Watts (W)	90
Lamp Operating Voltage (V)	92

RIO Reflector Performance Data


Light Output Ratio	93%
--------------------	-----

Physical Data/Requirements

Luminaire Type	Enclosed Rated
Base Designation	E40
See dimensions below	

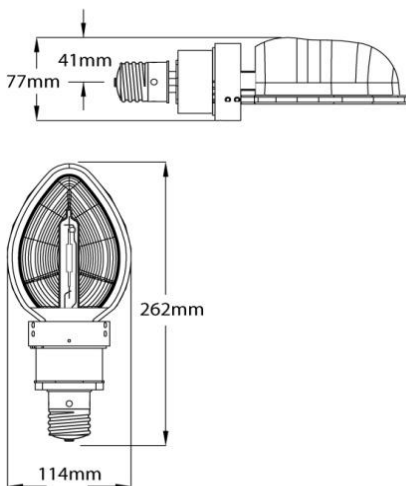

Typical light distribution at 8m mounting height

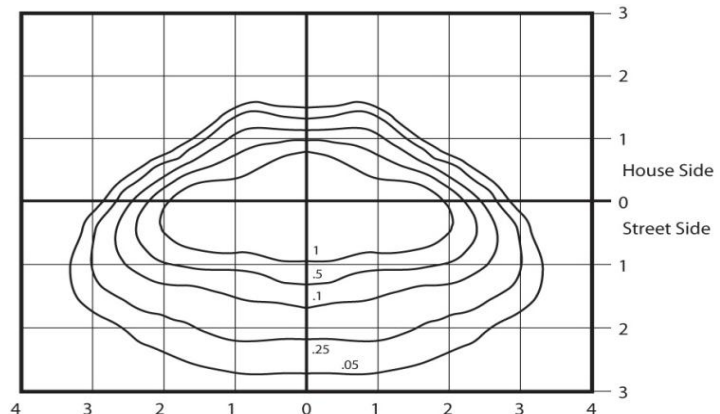

Notes:

Data is based upon tests performed by Venture Lighting in a controlled environment and is representative of relative performance at nominal power/voltage (110/240/415). Actual performance can vary depending on operating conditions. Data is subject to change without notice.