


Switch fuses 16...1250 Amperes

Designed for extreme conditions





Manual operation	OS Mini							OS							
DIN	OS16FD			OS40FD				OS32GD			OS125GD				
	OS35FD							OS63GD			OS160GD				
BS	OS20FB							OS32GB			OS100GB				
	OS32FB							OS63GB			OS125GB				
											OS160GB				
NFC	OS25FF							OS50GF			OS125GF				
	OS32FF														
UL/CSA	OS30FACC							OS60GJ			OS100GJ				
	OS30FAJ														
Switch size [A]	16	20	25	30	32	35	40	32	50	60	63	100	125	160	100
AC23/400 V [kW]	7.5	11	15	15	18.5			15	22	30		55	75		
AC23/415 V [kW]		7.5	15					15		30		55	55	75	
480 V [HP]			15							30					60
600 V [HP]			20							50					75

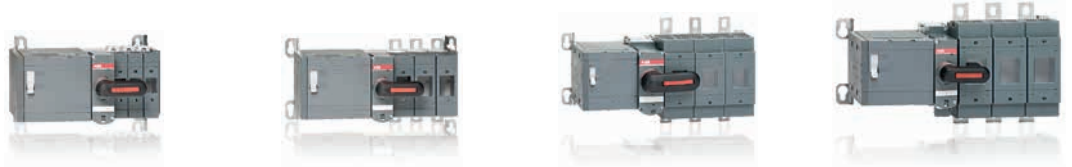

Motor operation	OSM														
DIN	OSM32GD			OSM125GD			OSM200D			OSM400D					
	OSM63GD			OSM160GD			OSM250D								
BS	OSM32GB			OSM100GB			OSM200B			OSM315B					
	OSM63GB			OSM125GB			OSM250B			OSM400B					
				OSM160GB											
NFC	OSM50GF			OSM125GF											
Switch size [A]	32	50	63	100	125	160	200	250	315	400					



OS200D		OS400D	OS630D	OS1250D
OS250D			OS800D	
OS200B		OS315B	OS630B	OS1250B
OS250B		OS400B	OS800B	
	OS200J	OS400J	OS600J	OS1200L
			OS800L	
200 250	200	315 400	600 630 800	1200 1250
110 140		230	355 450	560
110 145		180 230	355 450	560
	150	250	400 500	-
	200	350	500 600	-

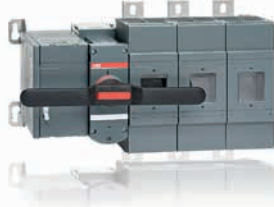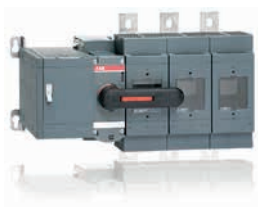

OSM630D	OSM1250D
OSM800D	
OSM630B	OSM1250B
OSM800B	
630 800	1250

- Accessories for switch fuses**
- Optional handles
 - Extended shafts
 - Auxiliary contacts
 - Fourth poles
 - N & PE terminals

- Solid links
- Terminal shrouds
- Connecting accessories
- Conversion kits
- Blown fuse indicators
- Locking accessories