


Deep groove ball bearings, single row, unsealed



| Principal dimensions | | | Basic load ratings | | Fatigue load limit P_u | Speed ratings | | Mass | Designation |
|----------------------|----|---|--------------------|--------|-----------------------------|-----------------|----------------|--------|-------------|
| d | D | B | dynamic | static | | Reference speed | Limiting speed | | |
| mm | | | kN | | kN | r/min | | kg | - |
| 15 | 24 | 5 | 1,56 | 0,8 | 0,034 | 60000 | 38000 | 0,0074 | 61802 |

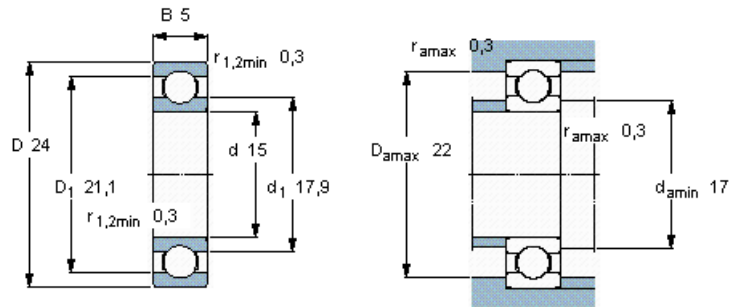

Calculation factors

k_r 0,015

f_0 10