


Item # 70-782EL11-1, 70782EL11-1 Socket / 10 Amp Rating, 300 Volts

11 Pin Ice Cube, Logic Style, DIN Panel Mount with Elevator Terminals, Module Compatible.

This Item is Normally Stocked

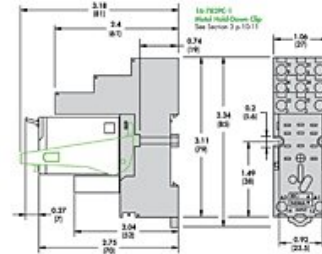

[Specifications](#) · [Electrical Rating](#) · [Temperature](#) · [Construction](#) · [Miscellaneous](#) · [Product Certifications](#)

Specifications

Check Inventory	Check Distributor Inventory
Contact Configuration	3PDT
Number of Terminals	11
Mounting Style	DIN Rail Panel

Electrical Rating

Current Rating	10 A
Nominal Voltage Rating	300 V

Temperature

Storage Range	- 40 to + 105 °C
----------------------	------------------

Construction

Protection Category (Finger Safe)	IP 20
Internal Metal Tracks	Copper Alloy Zinc Plated
Terminals	Steel Zinc Plated
Screw Style	Combination Head
Screw Size	M3 mm
Screw Torque 3 mm (Maximum)	7 / 0.8 Lb-in / Nm
Terminal Connection	Elevator
Terminal Layout	Logic
Base	Square

Miscellaneous

Wire Size Capacity (Maximum), EN 60204-1, Solid Cu	14 / 16 (2) AWG, 2.5 / 1.5 (2) mm ²
---	--

Wire Size Capacity (Maximum), EN 60204-1, Stranded Cu	14 / 16 (2) AWG, 2.5 / 1.5 (2) mm ₂
DIN Rail Mounting, EN 60715	35 mm
Chassis Mount Screw Torque	7 / 0.8 Lb-in / Nm
Flammability Rating	94V-0 Class
Body Color	Light Gray
DIN Locking Method	Red Plastic Locking Clip

Product Certifications

Agency Approvals	CE RoHS UL CSA
------------------	-------------------------