



# Datasheet


ENGLISH

## New 5.0mm Screwless 10A 2 Way

RS Stock 874-5461



### Dimensions: (mm)

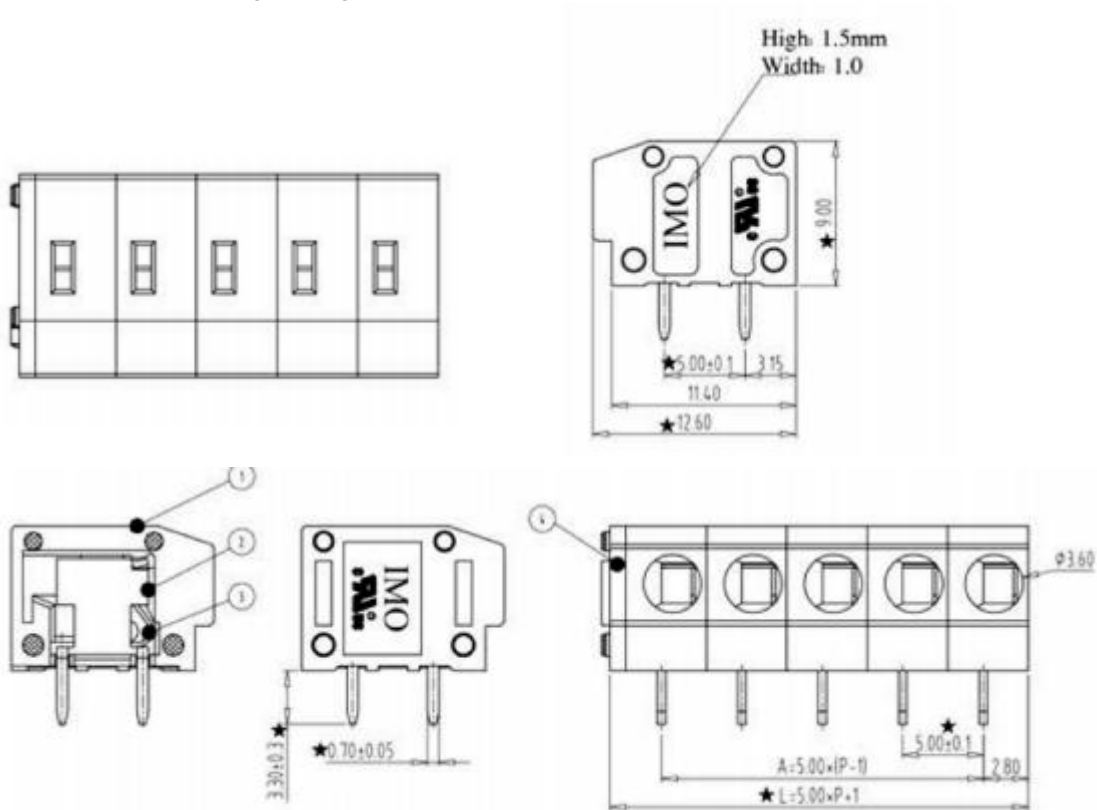



ENGLISH

## Specifications

- Rated Voltage: 300V 10A (UL)
- Insulation Resistance:  $\geq 500\Omega M$  or more at DC500V
- Withstanding Voltage: AC 1600V/1 min
- Temperature Range:  $-40^{\circ}C \sim +105^{\circ}C$
- Suitable Electric Wire: 14-20AWG
- Insulation Stripping Length: 8mm

## Materials

- Housing: PA66 / UL94V-0
- Spring Coil: Stainless Steel
- Solder pin: Brass / Tin Plated
- End Cover: PA66 (VO)