

# M 245



Euromas  
 Enclosure, polycarbonate

**Order no.: 02245000**

**Colour of enclosure group**

Light grey, similar to RAL 7035; special colours on request

**Protection class**


Depending on the model: IP 65 or IP 66/DIN EN 60529; IP 67 available on request for some sizes.

**Enclosure material**

ABS, PC (UV stabilised) and selected sizes in PC UL 94 V0 (additional UL 94 V0 versions on request), seal made of CR; for details see Technical Information

Scope of delivery: Lid and base, lid screws made of V2A, self-tapping screws for mounting bosses

Note: G = Design with crystal-clear lid.  
 IP = Ingress protection acc. to DIN EN 60529

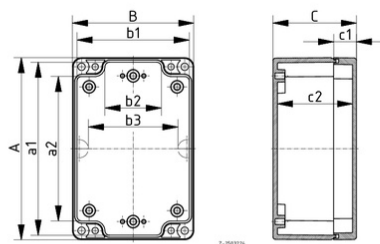

<b>A</b>	340 mm
<b>B</b>	150 mm
<b>C</b>	120 mm
<b>a1</b>	329,3 mm
<b>a2</b>	301,3 mm
<b>b1</b>	139,3 mm
<b>b2</b>	87,3 mm
<b>c1</b>	40 mm
<b>c2</b>	113 mm

**Technical drawings**

3D product data in STEP format:  
[Registration necessary](#)  
 Catalogue drawing in DXF format:  
[02245000\\_M-245.dxf](#) (672 KB)  
 Basic drawing for processing work:  
[02245000\\_M-245-G.dxf](#) (345 KB)  
 Catalogue drawing in PDF format:  
[02245000\\_M-245.pdf](#) (103 KB)

**Chapter download**

[Euromas\\_ABS\\_PC\\_GB.pdf](#) (338 KB)

\* = Available on request