
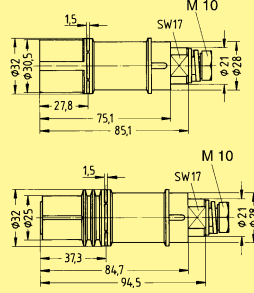

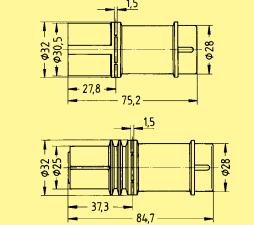

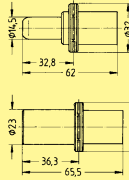


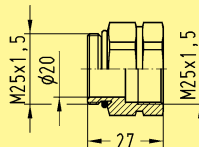
 




Modular
High Current Connector System

Identification	Part number		Wire gauge	Drawing	Dimensions in mm
	Male contact	Female contact			
<p>Contacts with Screw terminal for housing bulkhead mounting</p> 	09 11 001 2655	09 11 001 2755	for cable lug up to max. 120 mm ²		
<p>with Axial screw termination</p> 	09 11 001 2651 09 11 001 2652	09 11 001 2751 09 11 001 2752	35 ... 70 mm ² 95 ... 120 mm ²		
<p>PE contact with Axial screw termination</p> 	09 11 000 6156	09 11 000 6256	35 ... 70 mm ²		
<p>Hexagonal driver Adapter (SW 5)</p> 	09 99 000 0371				
Identification	Part number	M	SW	Drawing	Dimensions in mm
<p>Hexagonal adapter metal version with O-Ring</p> 	19 36 000 5134 19 36 000 5135	25 32	30 40		

Han HC
Modular

Stock items in bold type