

Datasheet

RS Pro Cable Clip 20.3mm Black PE

RS Stock No: **184-4621**



Product Details

RS Pro cable clip in black colour, has a maximum bundle diameter of 20.3 mm. The cable cleat is manufactured from low density polyethylene, which has high strength and impact resistance. The material is resistant to corrosion and UV light. It is stable at temperature of -30 to +60°C.


Features and Benefits

- Comes in black colour
- Low density polyethylene (LDPE) construction
- Temperature range from -30 to +60°C

Specifications:

Affixing Method	Screw
Cable Clip/Clamp Style	Cable Clip
Colour	Black
Depth	38 mm
Dimensions [L x W (x D)]	25 x 38 mm
Material	PE
Maximum Bundle Diameter	20.3 mm
Width	25 mm

- MS4 = RS 184-4609**
- MS5 = RS 184-5214**
- MS6 = RS 184-4615**
- MS7 = RS 184-5220**
- MS8 = RS 184-4621**
- MS9 = RS 184-4637**
- MS10 = RS 184-4643**

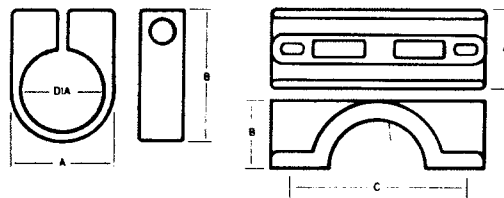

Dimensional Data

Reference Numbers	Dimensions			
	Width	Height	Fixing Centres	Clearance Bolt Holes
Standard Polypropylene	A	B	C	
	mm	mm	mm	mm
Single Fixing				
MS 5	17.5	28.0	N/A	6
MS 6	20.0	31.0	N/A	6
MS 7	23.0	34.0	N/A	6
MS 8	25.0	38.0	N/A	6
MS 9	28.5	41.0	N/A	6
MS10	30.0	43.5	N/A	6

Size:

MS 8

Qty:

50

Conductor size mm ²	Copper conductor wire armoured Number of cores			Aluminium conductor wire armoured Number of cores			MULTICORE CABLES					
							Conductor size					
				4			1.5mm ²	2.5mm ²	4mm ²			
1.5	5	5	6				5 core	6	7	8		
2.5	6	6	6									
4	6	7	7				7 core	6	7	9		
6	7	8	8									
10	8	9	9				10 core	8	9	11		
16	9	10	11	7	8	9						
25	10	11	12	9	10	12	12 core	8	9	11		
35	12	12	14	10	10	12						
50	7	11	12	14	8	10	12	14	19 core	9	10	12
70	8	12	14	16	8	12	14	16				
95	9	14	16	18	9	14	16	18	27 core	10	12	16
120	10	16	18	20	10		16	20				
150	11	16	18		12		18	20	37 core	12	14	
185	12	18			12		20					
240	14	20			14							
300	16				14				48 core	14	16	