

## Mini-Lynx Fast-Start

ML FAST-START 827 E27 15W SLV

0035116

### Range features



CE

### PRODUCT OVERVIEW

Ordering number	0035116
Technology	Compact Fluorescent
Light colour	827 Homelight
Energy class	A
Average life (Rated) (h)	10000
Lamp shape	Stick
Lamp finish	Frosted
Dimmable	No
Cap/Base	E27
Type	Mini-Lynx Fast Start T3 4U Stick
EAN code	5410288351162
CRI (Ra)	80
Colour temperature (K)	2700
Luminous flux (Rated) (lm)	900
Efficacy (Rated) (lm/w)	60
Watt (Nominal) (W)	15
Equivalent watt (W)	70
Voltage (V)	220-240

# Mini-Lynx Fast-Start

ML FAST-START 827 E27 15W SLV

0035116

## DATA TABLE

### General data

<b>Ordering number</b>	0035116
<b>Dry applications use only</b>	Yes
<b>Technology</b>	Compact Fluorescent
<b>Average life (Rated) (h)</b>	10000
<b>Average life (Nominal) (h)</b>	10000
<b>Energy class</b>	A
<b>Energy saving lamp</b>	Yes
<b>Lamp shape</b>	Stick
<b>Lamp finish</b>	Frosted
<b>Dimmable</b>	No
<b>Cap/Base</b>	E27
<b>Type</b>	Mini-Lynx Fast Start T3 4U Stick
<b>EAN code</b>	5410288351162
<b>E-number FI</b>	4940283
<b>E-number SE</b>	8357544
<b>Long description</b>	
<b>Product name</b>	ML FAST-START 827 E27 15W SLV
<b>Lamp mercury content (mg)</b>	<2.5
<b>Starting time (max) (s)</b>	< 1.0 Sec
<b>Warm-up time to 60% of full light (max) (s)</b>	< 40 s
<b>Control gear required</b>	No
<b>IEC Reference</b>	IEC 60968
<b>IEC Reference 2</b>	IEC 60969
<b>IEC Reference 3</b>	IEC 55015
<b>ILCOS code</b>	FBTH-15/27/1b-E27-48/114
<b>Intended purpose</b>	General lighting
<b>No. of switching cycles before premature failure (min)</b>	30000
<b>Special purpose lamp</b>	No
<b>Transformer required</b>	No
<b>Sales pack quantity</b>	10
<b>Optimal operating condition (°C)</b>	25° C, cap-up, Stated lumen output may vary if operated in non-standard position

# Mini-Lynx Fast-Start

ML FAST-START 827 E27 15W SLV

**0035116**

## Optical data

<b>Light colour</b>	827 Homelight
<b>CRI (Ra)</b>	80
<b>Colour temperature (K)</b>	2700
<b>Lumen maintenance at end of nominal life (%)</b>	= 75.0 %
<b>Luminous flux (Rated) (lm)</b>	900
<b>Luminous flux (Nominal) (lm)</b>	900
<b>Chromaticity coordinate Y</b>	0.420
<b>Chromaticity coordinate X</b>	0.463

## Electrical data

<b>kWh per 1000 hours burning time</b>	15
<b>Efficacy (Rated) (lm/w)</b>	60
<b>Watt (Nominal) (W)</b>	15
<b>Watt (Rated) (W)</b>	15
<b>Equivalent watt (W)</b>	70
<b>Voltage (V)</b>	220-240
<b>Current (A)</b>	0.110
<b>Lamp power factor</b>	> 0.55

## Physical data


<b>Weight (kg)</b>	0.07
<b>Lamp Length (mm) - C/L</b>	114
<b>Max. Lamp Diameter (mm) - D</b>	48
<b>Single packaging type</b>	Box/Sleeve
<b>Single package dimensions (L x W x H) (cm)</b>	4.80 x 4.70 x 12.50
<b>Outer package dimensions (L x W x H) (cm)</b>	25.30 x 11.10 x 14.50

## Mini-Lynx Fast-Start

ML FAST-START 827 E27 15W SLV

0035116

### TECHNICAL DRAWINGS

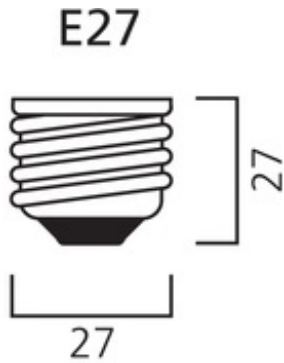

### ENERGY LABEL

