


Deep groove ball bearings, single row, shield on both sides



Principal dimensions			Basic load ratings		Fatigue load limit P_u	Speed ratings		Mass	Designation
d	D	B	dynamic	static		Reference speed	Limiting speed		
mm			kN	C_0	kN	r/min		kg	-
4	13	5	0,936	0,29	0,012	110000	53000	0,0031	624-2Z

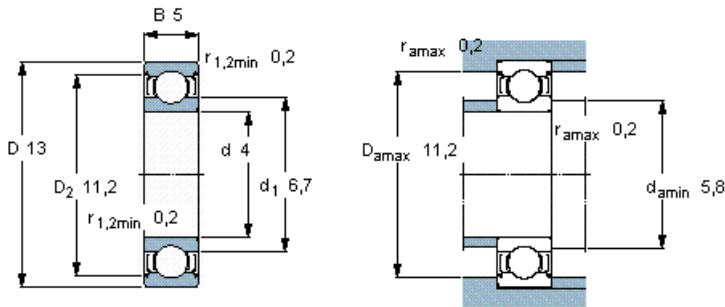

Calculation factors

k_f 0,025
 f_0 7,3