

This is a sample photo.


ORDER SYMBOL: AL 081806

EL.number **EAN:** 6418074004130
 Sweden: 2536315
 Denmark: 8212004663
 Finland: 3423613

INCLUDING:
 Enclosure body, cover with PUR gasket, cover screws, 4 mounting screws and 2 earth screws.

APPROVALS:
 USA: UL Type 1, 4, 4X, 12, 13 (E75645 Vol.1 Sec.6)
 EURO: IP 67/IP 66
 OTHERS: IEC 529

FIBOX EURONORM II AL

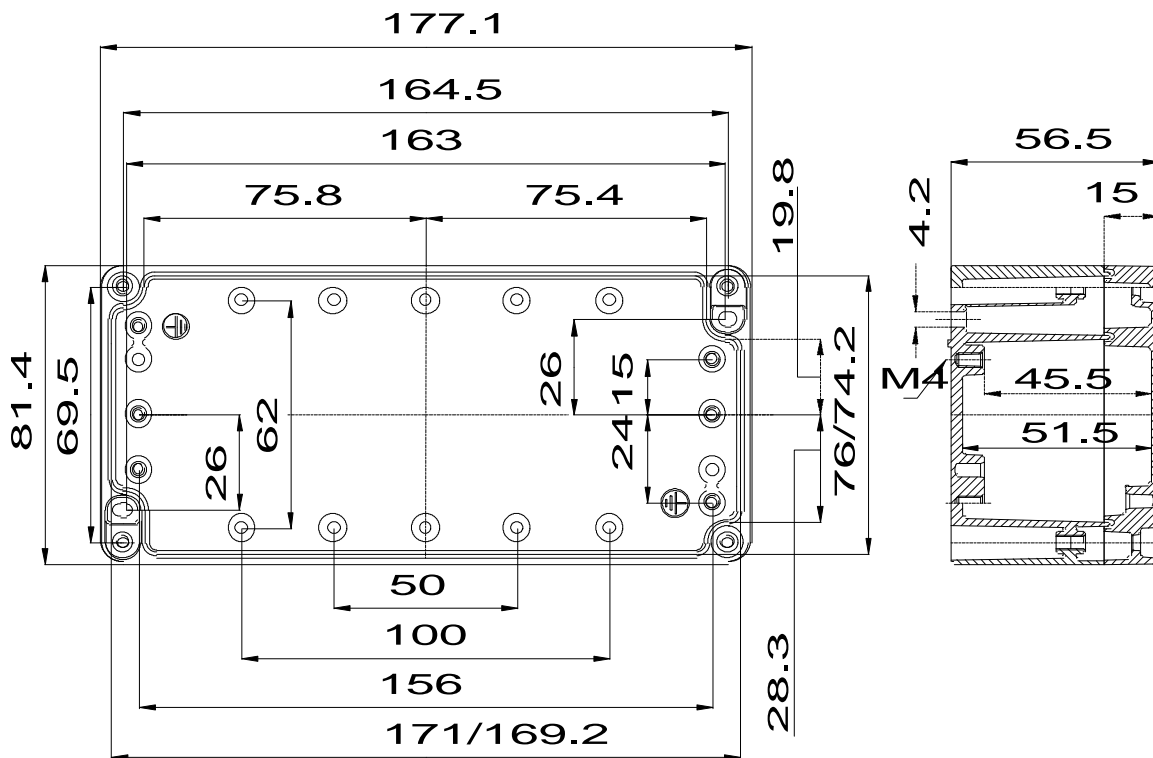

TECHNICAL INFORMATION:

Standard colour: RAL 7001	Temp.range in cont. use: Max. +80 °C
Ingress protection: IP 67 (IEC 529)	Temp. range of material: - 50 °C - + 120 °C
Flame resistance:	

ACCESSORIES

DIN-Rail	ARH 12	DIN-Rail	ARH 36	Fastening lug	MRS 28540
DIN-Rail	ARH 16	DIN-Rail	ARH 40	Fastening lug	MRS 28541
DIN-Rail	ARH 1636	DIN-Rail	ARH 60		
DIN-Rail	ARH 1656	DIN-Rail	ARM 0610		
DIN-Rail	ARH 22	DIN-Rail	ARM 0615		
DIN-Rail	ARH 2320	DIN-Rail	ARM 0808		
DIN-Rail	ARH 2328	DIN-Rail	ARM 0813		
DIN-Rail	ARH 2333	DIN-Rail	ARM 0818		
DIN-Rail	ARH 26	DIN-Rail	ARM 0825		