



Hexagon Metric

7400SM


DIN 3124/ISO 2725.

3/8" ● 10 DIN 3120/ISO 1174.

Finish: nickel and chrome-plated, fine-polished.


Material: VANADIUM-EXTRA.

With Dynamic-Drive Profile.

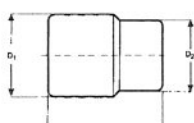

Dynamic-Drive-Profile

Low surface pressure due to large force-applying surfaces

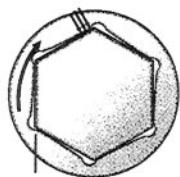

No notching sensitivity


Product code	EAN code 731415+		Dim. mm	L mm	D ₁ mm	D ₂ mm	
7400SM-6	1092917	5	6	28	9,3	17,5	15
7400SM-7	1092924	5	7	28	10,9	17,5	15
7400SM-8	1092931	5	8	28	12,1	17,5	16
7400SM-9	1092948	5	9	28	13,4	17,5	19
7400SM-10	1092955	5	10	28	14,6	17,5	19
7400SM-11	1092962	5	11	28	15,9	17,5	20
7400SM-12	1092979	5	12	28	17,1	17,5	22
7400SM-13	1092986	5	13	28	18,4	17,5	22
7400SM-14	1092993	5	14	28	19,6	19,0	23
7400SM-15	1093006	5	15	28	20,9	19,0	25
7400SM-16	1831127	5	16	28	22,1	20,0	25
7400SM-17	1093020	5	17	28	23,4	20,0	30
7400SM-18	1831134	5	18	28	24,6	21,0	30
7400SM-19	1093044	5	19	28	25,9	22,0	40

Double hexagon Metric

High performance sockets.


Thin-walled, with Dynamic-Drive-Profile.

A7400DM

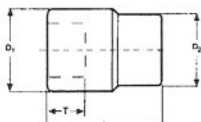

Dynamic-Drive-Profile

Low surface pressure due to large force-applying surfaces

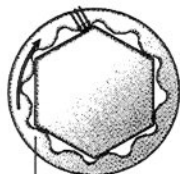

No notching sensitivity

Product code	EAN code 731415+		Dim. mm	L mm	D ₁ mm	D ₂ mm	T mm	
A7400DM-9	1819965	5	9	28	12,8	17,2	9,5	19
A7400DM-10	1819972	5	10	28	14,1	17,2	10,5	19
A7400DM-11	1819989	5	11	28	15,3	17,2	11,5	19
A7400DM-12	1819996	5	12	28	16,6	17,2	12,5	22
A7400DM-13	1820008	5	13	28	17,8	17,2	12,5	22
A7400DM-14	1820015	5	14	32	19,1	17,2	14,5	22
A7400DM-15	1820022	5	15	32	20,3	18	14,5	26
A7400DM-16	1820039	5	16	32	21,6	19	14,5	28
A7400DM-17	1820046	5	17	35	22,8	20	16	30
A7400DM-18	1820053	5	18	35	24,1	21	17	36
A7400DM-19	1820060	5	19	35	25,3	22	17,5	39
A7400DM-20	1820077	5	20	35	26,6	23	17,5	42
A7400DM-21	1820084	5	21	35	27,8	24	17,5	49
A7400DM-22	1820091	5	22	38	29,1	24	19,5	50

These sockets are applicable to all nuts and bolts used in the aerospace industry.

DIN	65546, 65438 - 65443,
LN	29520, 29542, 29550, 29551, 29769, 29901 - 29903, 29934,
	29955, 65056, 65101 - 65106, 65416 - 65418, 29529, 29894,
	29919, 65414,
VLN	29953,
EN	2907, 3013.