

## Datasheet

### **RS 1 Gang Outdoor Electrical Socket, Type G - British, 13A, Surface Mount, IP66**

**RS Stock number: 699-7095**



### Features

Stylish modern profile

Colour coded terminals with backed out captive screws for easy installation

Covers to seal the fixing screws

2 Earth terminals in socket except WP23 which has 1

1 Earth terminal in mounting box

All cable entries in the 4 sides have removable blanking caps.

Housing will accept accessories from the Nexus range

Cover will stay open to allow for easy access to sockets

See-through cover allows status of switches to be seen

Latched type, 30mA trip current, 40mS trip

## Product Images


**WP22/WP24**

**WP21/WP23**


### Technical Specifications ( WP21, WP22 products)

<b>Standard(s)</b>	BS 1363 Part 2
<b>Rating</b>	13 Amp 250V~
<b>Switch type</b>	Double pole
<b>Contact Gap</b>	3mm minimum
<b>Terminal Capacity</b>	3 x 2.5mm <sup>2</sup> 3 x 4mm <sup>2</sup> 2 x 6.0mm <sup>2</sup>
<b>IP rating</b>	IP56 with plug in use
<b>Covered by RoHS directive</b>	No
<b>Covered by WEEE directive</b>	No
<b>WP21</b>	
<b>Size</b>	111mm x 154mm x 80mm
<b>Number of cable entries</b>	5 x 20mm. 1 in each of 3 sides and 2 in the remaining side 1 drill out entry 20/25mm in rear face
<b>WP22</b>	
<b>Size</b>	171mm x 154mm x 80mm
<b>Number of cable entries</b>	8 x 20mm. 1 in each of the 2 sides and 3 in each of the top and bottom faces 1 drill out entry 20/25mm in rear face

### Technical Specifications ( WP23, WP24 products)

<b>Standard(s)</b>	BS 1363 Part 2
<b>Rating</b>	13 Amp 250V~
<b>Terminal Capacity</b>	3 x 2.5mm <sup>2</sup> 3 x 4mm <sup>2</sup> 2 x 6.0mm <sup>2</sup>
<b>IP rating</b>	IP56 with plug in use
<b>Covered by RoHS directive</b>	No
<b>Covered by WEEE directive</b>	No
<b>WP23</b>	
<b>Size</b>	111mm x 154mm x 80mm
<b>Number of cable entries</b>	5 x 20mm. 1 in each of 3 sides and 2 in the remaining side 1 drill out entry 20/25mm in rear face
<b>WP24</b>	
<b>Size</b>	171mm x 154mm x 80mm
<b>Number of cable entries</b>	8 x 20mm. 1 in each of the 2 sides and 3 in each of the top and bottom faces 1 drill out entry 20/25mm in rear face

WP22/WP24

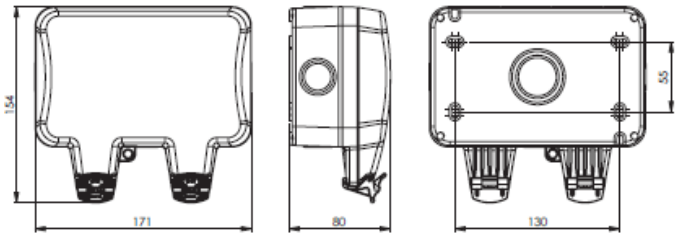

WP21/VP23

