

VARIO® LINEA


Overvoltage Protection acoustic 6+6-fold plus

- ✓ Robust plastic, grey
- ✓ Built-in Schuko plug sockets (90°rotated), round
- ✓ Space of sockets: 64 mm
- ✓ Available with 1,5 m power cord and angle plug as standard product;
Optional: also available with 3 m and 5 m power cable
- ✓ Acoustic fault message
- ✓ Increased safety due to integrated child protection
- ✓ End caps: mounting possible

Technical Data

- Voltage u_c U_c : 230 V~
- Rated current (-Power) 16 A (3600 W)
- Max. continuous operation voltage u_c U_c : 255 V~
- U_{oc} : 5000 V
- Protection level U_p : L-N < 1,0kV
L/N-PE < 1,5kV
- I_{max} (8/20) 6,5 kA
- Fuse: T6,3AH/250 V
- SPD according to EN 61643-11 Typ3
- Angle plug with earthing contact
- 2-pole, illuminated switch
- Consumption per switch: < 0,5 W
- Consumption overvoltage protection: < 0,1 W

Dimensions: 846 x 74 x 47 mm (L x W x H)
Fixing dimension: 838 mm
EAN: 4012096024088
Packaging unit: 10
Article no.: 0232x00062301

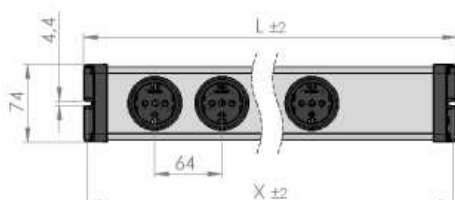

VARIO®
LINEA

Subject to technical changes.
Special designs on request.
Review Date: 04/2013