



Dummy module - HC-M-BM - 1676828

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)

Dummy module, for vacant slots in the metal retaining frame

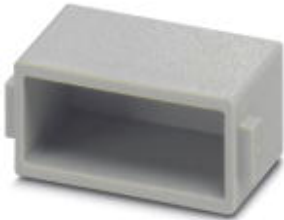

Key commercial data

Packing unit	2 pc
Minimum order quantity	2 pc
GTIN	 4 017918 129378
Weight per Piece (excluding packing)	5.67 g
Custom tariff number	85472000
Country of origin	Germany

Technical data

General

Material	PC
Inflammability class according to UL 94	V0

Classifications

eCl@ss

eCl@ss 4.0	27140816
eCl@ss 4.1	27140816
eCl@ss 5.0	27143424
eCl@ss 5.1	27143424
eCl@ss 6.0	27143424
eCl@ss 7.0	27440209
eCl@ss 8.0	27440209

ETIM

ETIM 2.0	EC000438
----------	----------

Dummy module - HC-M-BM - 1676828

Classifications

ETIM

ETIM 3.0	EC000438
ETIM 4.0	EC000438
ETIM 5.0	EC002608

UNSPSC

UNSPSC 6.01	30211923
UNSPSC 7.0901	39121522
UNSPSC 11	39121522
UNSPSC 12.01	39121522
UNSPSC 13.2	39121522

Approvals

Approvals


Approvals


UL Recognized / GOST

Ex Approvals

Approvals submitted

Approval details

UL Recognized 

GOST 
--

Drawings

Dummy module - HC-M-BM - 1676828

Dimensioned drawing



HC-M-BM