


677-0764

Description: Dual Reading Dial Caliper

Specification: 0-150mm/6"

Resolution: 0.02mm/0.001"


Accuracy:  $\pm 0.02\text{mm}/\pm 0.001\text{"}$

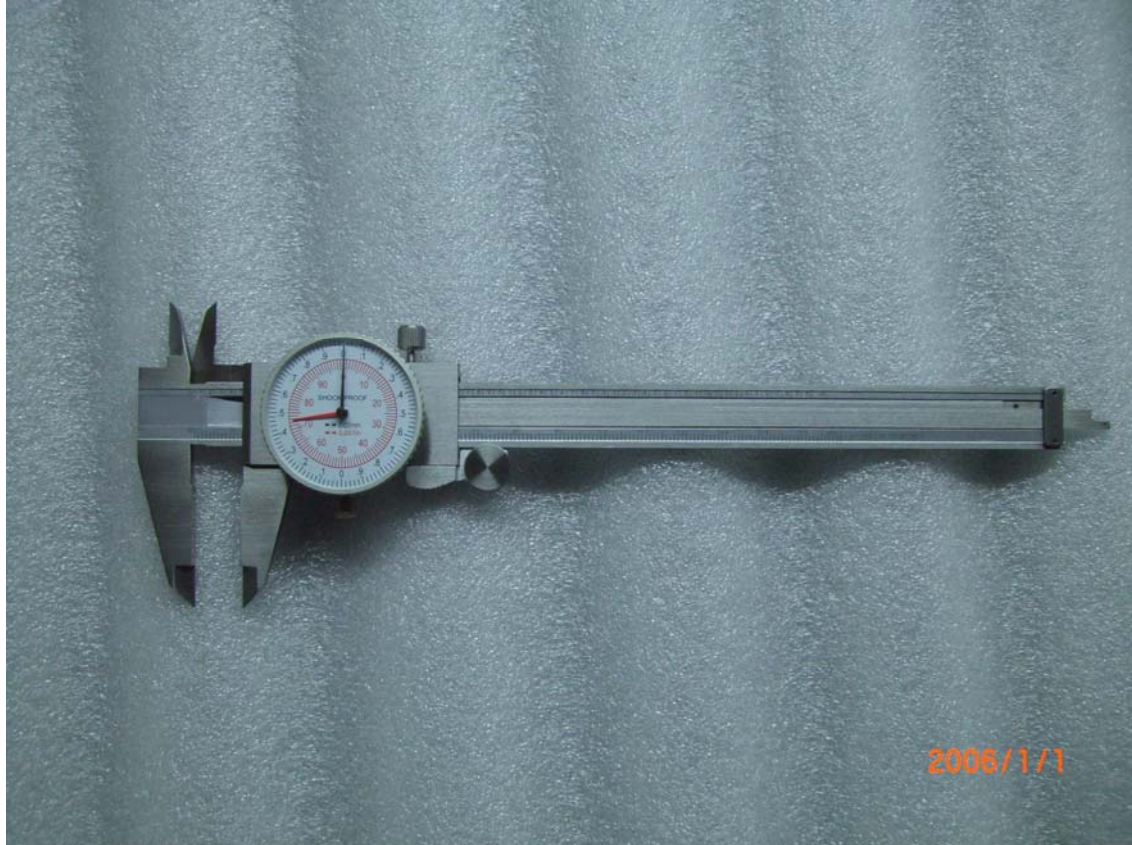

We manufacture the new combination English/metric dual reading dial calipers (patented). Eliminates the need for two dial calipers and reduces errors. You can get readings in English and metric from a dial at the same time.

### FEATURES

- Made of stainless steel throughout.
- All measuring faces is finished.
- Outer dial reads to .001".
- Suitable for: inside, outside, step&depth.
- One revolution, .100" per rev.
- Reads to .001"/.2mm.
- English&metric grad. on beam.
- Dial shockproof system.
- With fine-adjustment.
- Adjustable bezel.
- Fitted plastic case.

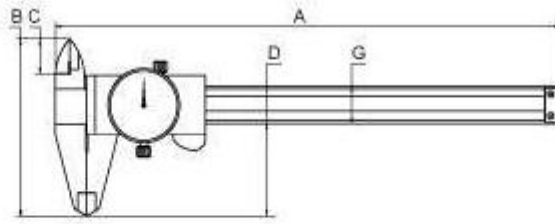

**Dimensions**

Range	A	B	C	D	G
0-100mm/0-4"	160mm	60mm	12.5mm	30mm	13mm
0-150mm/0-6"	234mm	77mm	16mm	40mm	16mm
0-200mm/0-8"	290mm	90.5mm	19mm	50mm	17mm