

Lamps :  
MR11 – MR16 12V LAMPS



**DICHROIC LAMPS CLOSED  
(2,000 HOURS)**

Code	Description
L25D	MR11 35mm – 20w 30°
L69D	MR16 50mm – 20w 38°
L94D	MR16 50mm – 20w 24°
Info:	Colour temperature: 3°K Warm White. Colour code: 830

Box QTY (Inner/Outer)	20/200	Price List Page No.	44
-----------------------	--------	---------------------	----



**DICHROIC LAMPS CLOSED  
(2,000 HOURS)**

Code	Description
L50D	MR16 50mm – 50w 24°
L58D	MR16 50mm – 50w 38°
L59D	MR16 50mm – 50w 60°
Info:	Colour temperature: 3°K Warm White. Colour code: 830

Box QTY (Inner/Outer)	20/200	Price List Page No.	44
-----------------------	--------	---------------------	----



**DICHROIC LAMPS CLOSED  
(2,000 HOURS)**

Code	Description
L22D	MR11 35mm – 35w 30°
L35D	MR16 50mm – 35w 24°
L70D	MR16 50mm – 35w 12°
L81D	MR16 50mm – 35w 38°
Info:	Colour temperature: 3°K Warm White. Colour code: 830

Box QTY (Inner/Outer)	20/200	Price List Page No.	44
-----------------------	--------	---------------------	----



**DICHROIC LAMPS CLOSED  
(2,000 HOURS)**

Code	Description
L58DB	MR16 50mm – 50w 38° Blue
L58DY	MR16 50mm – 50w 38° Yellow
L58DR	MR16 50mm – 50w 38° Red
L58DG	MR16 50mm – 50w 38° Green

Box QTY (Inner/Outer)	20/200	Price List Page No.	44
-----------------------	--------	---------------------	----

Lamps :  
PAR38 240V LAMPS



**80 WATT  
LAMPS**

Code	Description
PAR3880W	White
PAR3880B	Blue
PAR3880Y	Yellow
PAR3880R	Red
PAR3880G	Green
Info:	ES (E27) Fitting

Box Quantity	20	Price List Page No.	44
--------------	----	---------------------	----



**23 WATT ENERGY EFFICIENT  
LAMP (4,000 HOURS)**

Code	Description
PAR3823W	White
Info:	ES Fitting Low Energy Lamp. Colour temperature: 4°K Cool White. Colour code: 840

Box QTY (Inner/Outer)	1/15	Price List Page No.	44
-----------------------	------	---------------------	----



**DICHROIC LAMP CLOSED  
(2,000 HOURS)**

Code	Description
L58DAL	MR16 50mm – 50w 38°
L35DAL	MR16 50mm – 35w 20°
Info:	Aluminium Reflector. Colour temperature: 3°K Warm White. Colour code: 830

Box QTY (Inner/Outer)	20/200	Price List Page No.	44
-----------------------	--------	---------------------	----



**DICHROIC LAMP CLOSED  
(4,000 HOURS)**

Code	Description
L58DL	MR16 50mm – 50w 38°
Info:	Xenon Long Life Colour temperature: 3°K Warm White. Colour code: 830

Box QTY (Inner/Outer)	20/200	Price List Page No.	44
-----------------------	--------	---------------------	----

WARM WHITE:  
THE COLOUR OF MOST  
HALOGEN LAMPS.  
APPEARS SLIGHTLY  
"WHITER" THAN  
ORDINARY INCANDESCENT  
LAMPS.

COOL WHITE:  
GIVES A MORE CLINICAL  
OR "HIGH TECH" FEEL



**ENERGY EFFICIENT  
LAMPS**

Code	Description
PAR3860W	60w White
PAR38120W	120w White
Info:	ES Fitting Low Energy Lamp. Colour temperature: 4°K Cool White. Colour code: 840

Box Quantity	1/20	Price List Page No.	44
--------------	------	---------------------	----

# Lamps



Lamps :  
**3W HI POWER LED LAMPS**



**3W 50MM 240V**

Code	Description	Code	Description
3WGULEDW	3W White	3WGULEDB	3W Blue
3WGULEDY	3W Yellow	3WGULEDR	3W Red
3WGULEDG	3W Green		

Box QTY (Inner/Outer) **1/10** Price List Page No. **45**

Lamps :  
**MR16 LED DICHROIC LAMPS**



**DICHROIC LAMPS 50MM CLOSED**

Code	Description	Code	Description
MR16LEDW	White	MR16LEDR	Red
MR16LEDB	Blue	MR16LEDG	Green
MR16LEDY	Yellow		

Info: All 1W 50mm Closed. 21 LEDs. Can be used in MR16 Downlights  
Box QTY (Inner/Outer) **10/100** Price List Page No. **45**



OUR NEW 240V GU10 13W ENERGY EFFICIENT LAMP, WITH ITS UNIQUE HEAT SINK ABSORBING FEATURE, IS IDEAL FOR USE IN OUR FIRE-RATED DOWNLIGHTS. SEE PAGE 50-52

Lamps :  
**240V GU10 ENERGY EFFICIENT LAMPS**



GU1013W GU107/09/11W

**COMPACT FLUORESCENT LAMPS**

Code	Description
GU107W	7W
GU109W	9W
GU1011W	11W
GU1013W	13W

Info: Colour temperature 2.7°K - 3°K Warm White.

Box Quantity **10/100** Price List Page No. **46**

Lamps :  
**GU10 - GZ10 LAMPS (L = LONG LIFE)**



**HALOGEN REFLECTOR LAMP 50MM 240V FLOOD**

Code	Description
GU10L	40° (50w)
GU10-25L	40° (25w)
GU10-35L	40° (35w)

Info: Xenon long life 3000 hours. Colour temperature: 3°K Warm White. Colour code: 830

Box QTY (Inner/Outer) **10/100** Price List Page No. **45**



**HALOGEN REFLECTOR LAMP 50MM 240V FLOOD**

Code	Description
GZ10	40° (50w)
GU10	40° (50w)
GU10-25	40° (25w)
GU10-35	40° (35w)

Info: 2,000 hours. Colour temperature: 3°K Warm White. Colour code: 830

Box QTY (Inner/Outer) **10/100** Price List Page No. **45**

Lamps :  
**GU10 LED LAMPS**



**GU10 LED LAMPS**

Code	Description	Code	Description
GU10LEDW	White	GU10LEDR	Red
GU10LEDB	Blue	GU10LEDG	Green
GU10LEDY	Yellow		

Info: All 1.8W 50mm Closed. 21 LEDs. Can be used in GU10 Downlights  
Box QTY (Inner/Outer) **10/100** Price List Page No. **46**

Lamps :  
**GU10 COLOUR CHANGE LED LAMP**



**GU10 RED/GREEN/BLUE SEQUENTIAL COLOUR CHANGE**

Code	Description
GU10LEDV	1.8W 50mm Closed. 21 LEDs

Box QTY (Inner/Outer) **10/100** Price List Page No. **46**


Lamps :  
**HALOGEN LAMPS**



**TUNGSTEN HALOGEN LAMPS**

Code	Description
L110	118mm 500w - 110v
L150	78mm 150w - 240v
L200	118mm 200w - 240v
L300	118mm 300w - 240v
L500	118mm 500w - 240v
L1000	189mm 1000w - 240v
For use with FLO4BK. See page 68	
L1000-A	254mm 1000w - 240v

Box Quantity **50** Price List Page No. **46**

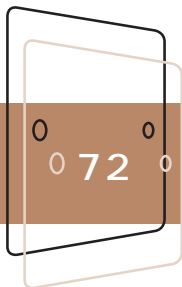


Lamps :  
**2D WHITE ENERGY EFFICIENT LAMPS**



**2D LOW ENERGY LAMPS**

Code	Description	Code	Description
2D16W2P	16w -2 Pin	2D28W2P	28w -2 Pin
2D16W4P	16w -4 Pin	2D28W4P	28w -4 Pin
Info:	5,000 hours. Colour temperature: 3.5°K White. Colour code: 835		
Box QTY (Inner/Outer)		10/40	Price List Page No. 46

Lamps :  
**PL LAMPS**

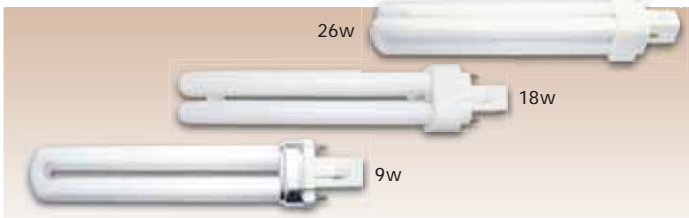

**PL LOW ENERGY LAMPS**

Code	Description	Code	Description
PL9W2P	9w 2-Pin	PL26W2P	26w 2-Pin
PL18W2P	18w 2-Pin	PL26W4P	26w 4-Pin
PL18W4P	18w 4-Pin	PL55W4P	55w 4-Pin
Info:	5,000 hours. Colour temperature: 4.0°K Cool White. Colour code: 835		
Box QTY (Inner/Outer)		10/40	Price List Page No. 47

Lamps :  
**CAPSULE LAMPS**



**G4 HALOGEN CAPSULE LAMPS**

Code	Description
LVL1	12v 10w - M91
LVL2	12v 20w - M47
LVL3	12v 50w - M32
Info:	Colour temperature 3°K Warm White. Colour code: 830
Box QTY (Inner/Outer)	
20/1000	Price List Page No. 46



**G9 BASE TUNGSTEN DOUBLE FUSED HALOGEN LAMPS**

Code	Description
G9-25W	240v Clear
G9-40W	240v Clear
G9-60W	240v Clear
Info:	Colour temperature 3°K Warm White. Colour code: 830
Box QTY (Inner/Outer)	
20/1000	Price List Page No. 47

Lamps :  
**HALOGEN ENERGY SAVING LAMPS**

NEW



**CANDLE, FLAME & GLS ENERGY SAVING LAMPS**

Code	Description	Equivalent Watt Incandescent
HALO-C28BC	28W Candle BC Clear Lamp	40w
HALO-C28SBC	28W Candle SBC Clear Lamp	40w
HALO-C28SES	28W Candle SES Clear Lamp	40w
HALO-C42BC	42W Candle BC Clear Lamp	60w
HALO-C42SBC	42W Candle SBC Clear Lamp	60w
HALO-C42SES	42W Candle SES Clear Lamp	60w
HALO-F28BC	28W Candle Flame BC Clear Lamp	40w
HALO-F28SBC	28W Candle Flame SBC Clear Lamp	40w
HALO-F28SES	28W Candle Flame SES Clear Lamp	40w
HALO-F42BC	42W Candle Flame BC Clear Lamp	60w
HALO-F42SBC	42W Candle Flame SBC Clear Lamp	60w
HALO-F42SES	42W Candle Flame SES Clear Lamp	60w
HALO-G28BC	28W GLS BC Clear Lamp	40w
HALO-G28ES	28W GLS ES Clear Lamp	40w
HALO-G42BC	42W GLS BC Clear Lamp	60w
HALO-G42ES	42W GLS ES Clear Lamp	60w
HALO-G52BC	52W GLS BC Clear Lamp	75w
HALO-G52ES	52W GLS ES Clear Lamp	75w
HALO-G70BC	70W GLS BC Clear Lamp	100w
HALO-G70ES	70W GLS ES Clear Lamp	100w
Info:	This new range of lamps combines the versatility of halogen with the advantages of 30% energy savings. They are fully dimmable and available in GLS, Candle and Flame Tipped.	
Box QTY (Inner/Outer)		10/100
		Price List Page No. 47

Lamps :  
**KNOW YOUR LAMPS**



**Halogen Lamps**  
GU4 (MR11) and GU5.3 (MR16) are both low voltage and push fit. GU10 and GZ10 are twist and lock mains voltage fittings.

**SBC = Small Bayonet Cap**  
**BC = Bayonet Cap**  
This very popular push and twist lamp is used throughout the UK and comes in two sizes.



**Single/Double Turn Compact Fluorescent Lamps (CFLs)**  
These lamps are commonly used in PL downlights, modular fittings and floodlights. 2-pin and 4-pin versions are available.

**SES = Small Edison Screw**  
**ES = Edison Screw**  
**GES = Giant Edison Screw**  
The Edison Screw or ES lamp fitting is used worldwide in a vast and varied range of applications. The most popular ES or E27 is widely used in the US and Europe. The SES is often used in decorative fittings such as chandeliers. The GES is more commonly used in industrial fittings.



**Halogen Capsule Lamps (G4 and G9)**  
G4 is a low voltage lamp widely used in under cabinet lights etc., and the G9 in mains downlights and decorative fittings.

