


Covering hood - HC-RBO 8-FE - 3247968


Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)

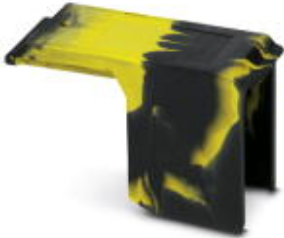

Covering hood, Connection method: Bolt connection, Width: 29 mm, Height: 33 mm, Color: black/yellow



Key commercial data

Packing unit	10 pc
Minimum order quantity	10 pc
GTIN	 4 046356 719247
Weight per Piece (excluding packing)	11.77 g
Custom tariff number	85389099
Country of origin	China

Technical data

General

Color	black/yellow
Inflammability class according to UL 94	V0

Dimensions

Width	29 mm
Length	140 mm
Height	33 mm
Height NS 35/7,5	33 mm
Height NS 35/15	40.5 mm

Connection data

Connection method	Bolt connection
-------------------	-----------------

Classifications

eCl@ss

eCl@ss 4.0	27141111
------------	----------

Covering hood - HC-RBO 8-FE - 3247968

Classifications

eCl@ss

eCl@ss 4.1	27141111
eCl@ss 5.0	27141140
eCl@ss 5.1	27141140
eCl@ss 6.0	27141140
eCl@ss 7.0	27141140

ETIM

ETIM 3.0	EC000489
ETIM 4.0	EC000897
ETIM 5.0	EC000897

UNSPSC

UNSPSC 6.01	30211827
UNSPSC 7.0901	39121424
UNSPSC 11	39121424
UNSPSC 12.01	39121424
UNSPSC 13.2	39121424