
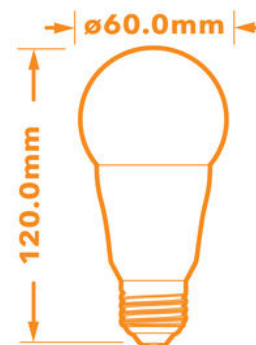


Verbatim LED Classic A E27 13W 2700K Warm White 1000 LM DIM


- E27 Socket
- 220 - 240 Voltage
- 30,000 hours Lifetime
- Dimmable
- 82% Energy Saving
- Lumen: 1000
- Equivalent to 71W incandescent bulb

Product Number	52152
General Data	
Lamp Socket	E27
Electric Data	
Wattage (W)	13
Wattage Equivalent (W)	71
Voltage (V)	220 - 240
Dimmable	yes
Power Factor	0.90
Operating Frequency (Hz)	50-60
Geometric Data	
Length (mm)	120
Diameter (in mm)	60
Weight (g)	202.5
Photometric Data	
Luminous Flux (lm)	1000
CRI	≥ 80
CCT (K)	2700
Beam Angle (°)	130
Luminous Efficacy (lm/W)	76.9
Lifetime (hrs)	30,000
Switching Cycle	20,000

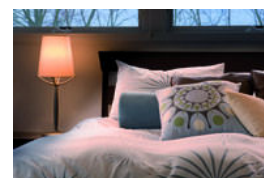

02/07/2014

Photometric Diagrams

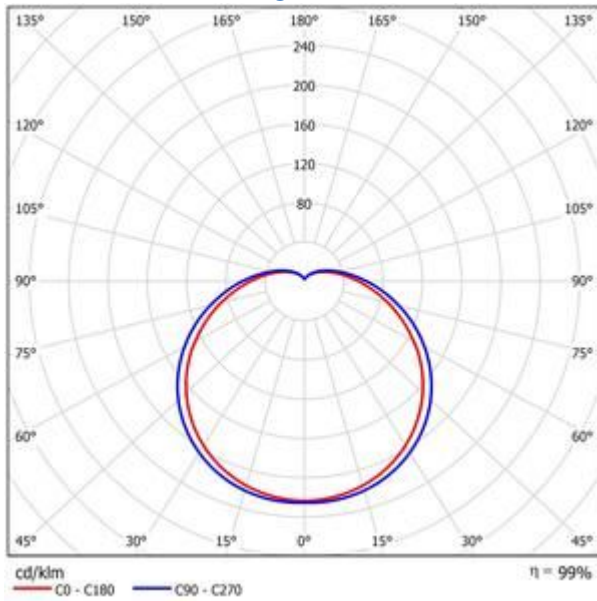


0.5	2.86 2.30	E(0°) E(C90) E(C0)	995 18 32
1.0	5.71 4.60	E(0°) E(C90) E(C0)	249 5 8
1.5	8.57 6.90	E(0°) E(C90) E(C0)	111 2 4
2.0	11.42 9.20	E(0°) E(C90) E(C0)	62 1 2
2.5	14.28 11.50	E(0°) E(C90) E(C0)	40 1 1
3.0	17.13 13.80	E(0°) E(C90) E(C0)	28 1 1

Distance [m] Cone Diameter [m] Illuminance [lx]

— C0 - C180 (Half-value Angle: 133.0°)
— C90 - C270 (Half-value Angle: 141.4°)

Energy Rating

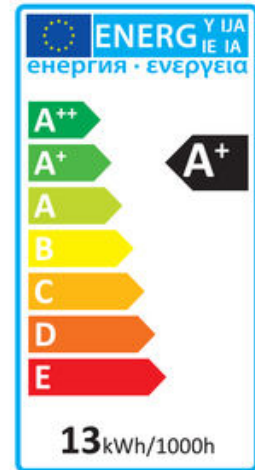

Technical Packaging Details

Barcode

023942521525

EAN 128

(02)00023942521525(37)04(91)204

EAN 14

50023942521520

Pack Dimensions(HxWxL)

178 x 118 x 61

Pack Weight

229

MOQ

4

Carton Dimensions (HxWxL)

195 x 144 x 253

Cartons/Pallet

80

Layers/Pallet

4

Units/Pallet

320

02/07/2014