

Flat Cable Connectors SEK

- har-mik®
- D-Sub
- InduCom

Applications



Product details


09 18 564 5323
IDC male connector

Connector size	64 contacts
Termination	Angled solder pin
Profile	Low-profile male header
Moulding	Standard Material
Termination length	2.9 mm
Performance level	AU-0.76•m [30• Inch]
RoHS compliant	Yes

Available Downloads

Title	Format	
Data sheet	PDF	download
CAD data 2D	DXF	download
CAD data 3D	IGES	download
CAD data 3D	STEP	download

Inquiry

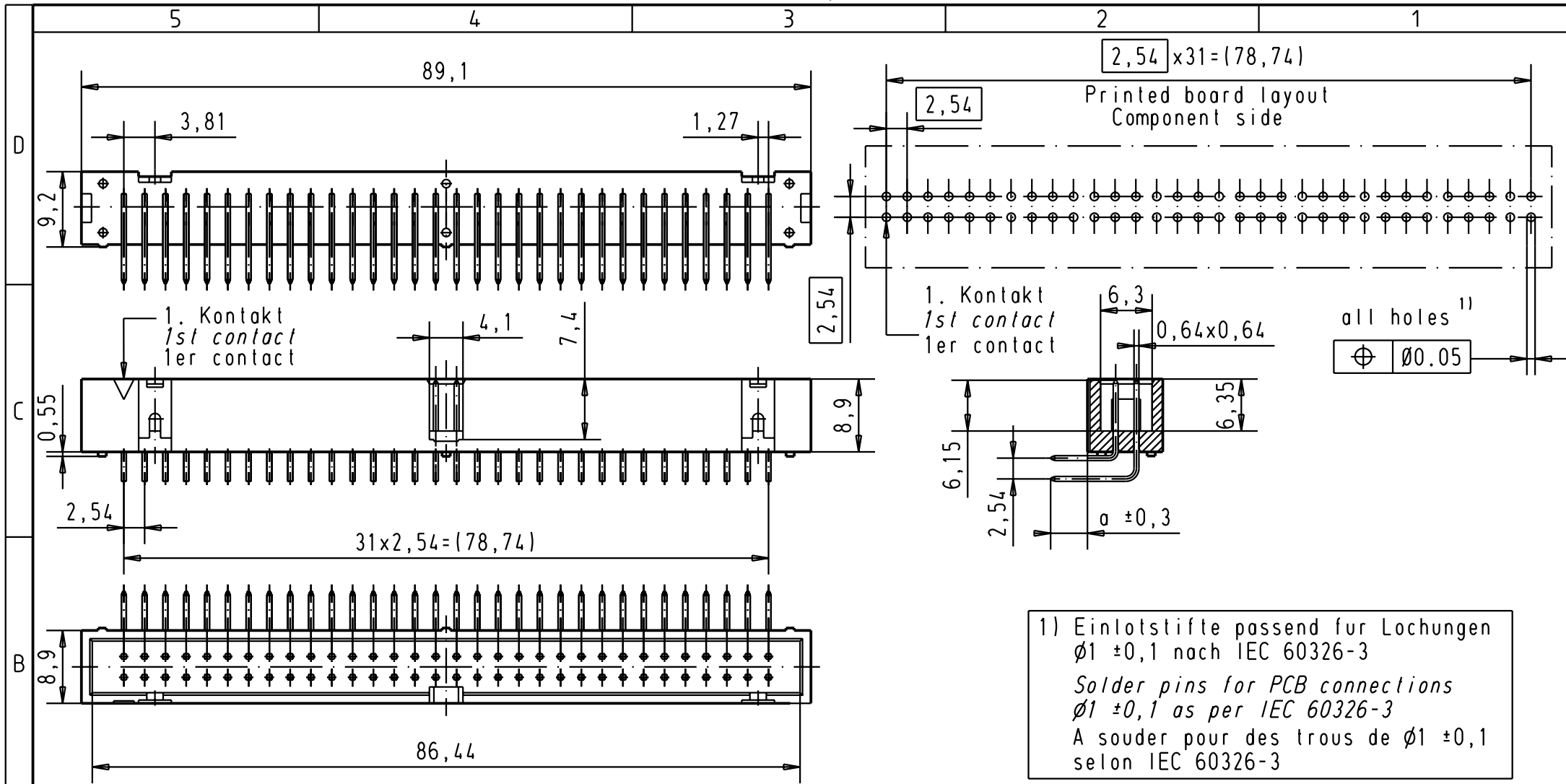

A	09185647321	3	4,5		All Dimensions in mm Original Size DIN A 4				Techn. Character.			Nicht tolerierte Masse! <i>Free size tolerances</i>		
	09185646321	2	4,5											
	09185645321	0,76 µm Au	4,5									SEK 18 Male connector 64 poles low profile with angled pins		
	09185647323	3	2,9								1,5:1			
	09185646323	2	2,9											
	09185645323	0,76 µm Au	2,9											
	Bestell-Nr. Part-No. Reference	Anforderungsstufe <i>performance level</i> Niveau de qualite	a	31502	03-JUN-03	JB	HARTING EURL F-95972 Paris			TB 0918564x32x		Blatt/ page 2/2		
26570				01-FEB-00	JB									
Mod.				Dat.	Name	Sub.								