

# Housing - HC-ADV-B24-BHFH-EEE - 1408915

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



HEAVYCON ADVANCE B24 basic housing without screw openings, for M6 screw locking, salt-water-resistant aluminum, without surface coating



## Key commercial data

Packing unit	1 pc
GTIN	 4 046356 582230
Weight per Piece (excluding packing)	559.4 g
Custom tariff number	85389099
Country of origin	China
Note	Made to Order (non-returnable)

## Technical data

### Dimensions

Height	72 mm
Width	45 mm
Length	152 mm

### Ambient conditions

Degree of protection of housing (IP)	IP66
	IP68 (0.2 bar/24 h)
	IP69K
Degree of protection of housing (NEMA)	4 (UL50e / NEMA 250)
	4X (UL50e / NEMA 250)
	6P (UL50e / NEMA 250)
	12 (UL50e / NEMA 250)
Ambient temperature (operation)	-40 °C ... 125 °C

### General

Note	For contact inserts HC-B24, BB46, D64, DD104, M, K
Type	B24

# Housing - HC-ADV-B24-BHFH-EEE - 1408915

## Technical data

### General

Housing type	Basic housing
Locking type	M6 screw locking
Cable exit	Variable
Housing material	Die-cast aluminum, corrosion resistant
Housing surface material	Uncoated
Assembly instructions	For cutting the screw connection thread yourself (M40 maximum)
Connection	To ensure optimum shielding, any insulating powder coating must be removed from the seal area on the control cabinet panel

## Classifications

### eCl@ss

eCl@ss 4.0	27140816
eCl@ss 4.1	27140816
eCl@ss 5.0	27143424
eCl@ss 5.1	27143424
eCl@ss 6.0	27261203
eCl@ss 7.0	27440202
eCl@ss 8.0	27440202

### ETIM

ETIM 4.0	EC000437
ETIM 5.0	EC000437

### UNSPSC

UNSPSC 6.01	31261502
UNSPSC 7.0901	31261502
UNSPSC 11	31261502
UNSPSC 12.01	31261502
UNSPSC 13.2	31261502

## Approvals

### Approvals

---

#### Approvals

#### EAC

---

#### Ex Approvals

---

# Housing - HC-ADV-B24-BHFH-EEE - 1408915

## Approvals

Approvals submitted

---

### Approval details

EAC
-----

## Accessories

### Accessories

#### Protective cover

Protective covers - HC-B 24-TMS-SD-IP65 - 1690804



HEAVYCON ADVANCE B24 IP65 protective cover, for panel mounting side, with screw locking, with retaining cord, diameter of retaining cord eyelet: 3 mm

---

Protective covers - HC-B 24-TMS-SD-IP50 - 1690765




HEAVYCON ADVANCE IP50 protective cover B24, for panel mounting side, with clip locking, with retaining cord, diameter of retaining cord eyelet 3 mm

---

## Drawings

Dimensioned drawing

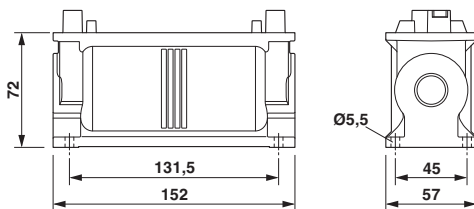

Dimensional drawing