

QL-700

High-Speed Professional Label Printer



Print up to 93 labels per minute*




Convenient drop-in rolls let you switch label sizes in seconds



Design your own labels, or choose from a variety of eye-catching, pre-made designs

*Using standard address labels, text only, at 300 x 300 dpi.

www.pbSmartPostage.com

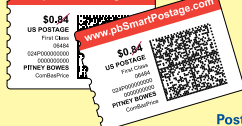

**Print Postage from
your Desktop**

Postage powered by

pbSmartPostage™

Enrollment in the pbSmartPostage™ service necessary, internet connection and postage label roll required

Images are for illustrative purposes only.

brother®
at your side

QL-700



Versatile Label & Postage Printer Helps You Work Smarter

Key Features

- Create cost-effective paper labels for packages, envelopes, file folders, CDs/DVDs, banners, postage and more
- Ultra-fast printing up to 93 labels per minute[†]
- Uses continuous paper and tape rolls for banners and signs up to 3 ft. long
- The Label Collection feature provides eye-catching, pre-designed labels and banners with commonly-used text[^]
- Auto cutter provides precise cuts for printing 1 or multiple custom-sized labels at a time
- High-resolution printing (up to 300 x 600 dpi), for crisp text and graphics
- Plug & Label feature lets you type and print labels without installing software[^]
- Export text directly from common applications such as Microsoft® Word®, Excel®, and Outlook® to create labels without retyping
- Connects via USB to your PC or Mac[□]

Print Postage right from your Desktop[†]

With the new Brother™ QL-700 and pbSmartPostage™, you can print the postage you need, when you need it, anytime.

**Save trips to the Post Office to buy stamps.
No software to download. It couldn't be easier.**

For more information or to enroll, visit
www.pb.com/brother

[†]Using standard address labels, text only, at 300 x 300 dpi. [^]Enrollment in the pbSmartPostage™ service necessary, Internet connection, and postage label roll required. pbSmartPostage™ service compatible with Windows only.
[□]Windows only. [□]Compatible with Windows® XP, Windows Vista®, Windows® 7, and Mac OS X 10.4.11–10.7.

© 2011 Brother International Corporation, 100 Somerset Corporate Blvd., Bridgewater, NJ 08807.

For more information visit our Website at www.brother.com or call 1-877-BROTHER

pbSmartPostage is a trademark of Pitney Bowes Inc. Brother is a trademark of Brother Industries Ltd. in the U.S. and/or other countries. Windows and Windows Vista are registered trademarks of Microsoft Corporation in the U.S. and/or other countries.

QL-700 Specifications

General	Operation Modes	PC Connected Only
	Cutter	Auto
	Cutter Life	Up to 300,000 (die-cut labels), 150,000 (continuous labels)
	Maximum Print Speed [†]	Up to 93 labels per minute
	Tape Sizes	Die-cut and Continuous DK Labels and Tapes
	Maximum Tape Width (inches)	2.4"
	Maximum Label Length	3 feet
	Maximum Resolution (dpi)	300 x 600 (Superfine Mode)
	Font Styles	TrueType
	Multiple Copies	Up to 9999 copies
Software	Postage Ready [†]	Yes
	Bar-Codes Types	CODE39, CODE128, UCC/EAN128 (GS1-128), ITF(I-2/5), CODABAR (NW-7), UPC-A, UPC-E, EAN13, EAN8, ISBN-2 (EAN13 AddOn2), ISBN-5 (EAN13 AddOn5), Laser Barcode, POSTNET, RSS (RSS14 Standard, RSS14 Truncated, RSS14 Stacked, RSS14 Stacked Omni, RSS Limited, RSS Expanded, RSS Expanded Stacked), PDF417 (Standard, Truncate, Micro), QR code (Model1, Model2, Micro), Data Matrix (ECC Square, ECC Rectangular), MaxiCode (Model2, Model3, Model4, Model5)
	Database File Compatibility	csv, txt, mdb, xls (Windows®) / csv, txt (Mac®)
System Requirements	Built-in Plug & Label Software [^]	Yes
	Included Software	P-touch® Editor 5.0 for Windows®, P-touch® Address Book 1.1, P-touch® Editor 5.0 for Mac®
	Microsoft® Add-ins	Microsoft® Word® / Outlook® / Excel® (Windows Only)
Other	Compatibility	Windows® & Mac®
	Operating System	Windows® XP, Windows Vista®, Windows® 7; Mac OS X 10.4.11 - 10.7
	Interface	USB
Other	Carton Contents	P-touch® Editor Software & Drivers, USB Cable, Power Cord, Quick Setup Guide, Starter rolls: DK-1201 Die-cut Standard Address Labels (100 labels), plus DK-2205 2.4" Continuous Length Paper Tape (26.2 ft.)
	Housing Dimensions	5.0" x 8.7" x 6.0"
	Warranty	2 Year Limited Warranty & Replacement Service

Wide Variety of Labels and Tapes



DIE-CUT PRE-SIZED LABELS*

ADDRESS LABELS

Small Address Label – 1.1 in. x 2.4 in., 800 labels per roll
Standard Address Label – 1.1 in. x 3.5 in., 400 labels per roll
Large Address Label – 1.4 in. x 3.5 in., 400 labels per roll

SHIPPING LABELS

Shipping Label – 2.4 in. x 3.9 in., 300 labels per roll

MULTI-PURPOSE LABELS

Multi-Purpose / Return Address Label – 0.66 in. x 2.1 in., 400 labels per roll
File Folder Label – 0.66 in. x 3.4 in., 300 labels per roll
Small Round Label – 0.47 in., 1200 labels per roll
Round Label – 0.94 in., 1000 labels per roll
CD/DVD Film Label – 2.2 in., 100 film labels per roll



CONTINUOUS LENGTH LABELS*

WHITE PAPER TAPES

Wide Tape – 2.4 in. x 100 ft.
Medium Width Tape – 1.1 in. x 100 ft.
Narrow Width Tape – 0.47 in. x 100 ft.
Removable Tape – 2.4 in. x 100 ft.**
Wide, Non-adhesive Tape – 2.1 in. x 100 ft. (for name badges)

DURABLE FILM TAPES

Wide Tape – 2.4 in. x 50 ft.***
Medium Width Tape – 1.1 in. x 50 ft.

* All labels and tapes are white unless otherwise noted. Additional purchase required.
** Yellow also available.
*** Yellow and clear also available.



Working with you for a better environment
www.brotherearth.com



brother®
at your side