




ENGLISH

Datasheet

RS 3 pairs , 100m CW1308 Twisted Telecom Cable

Stock Number - 520-2633

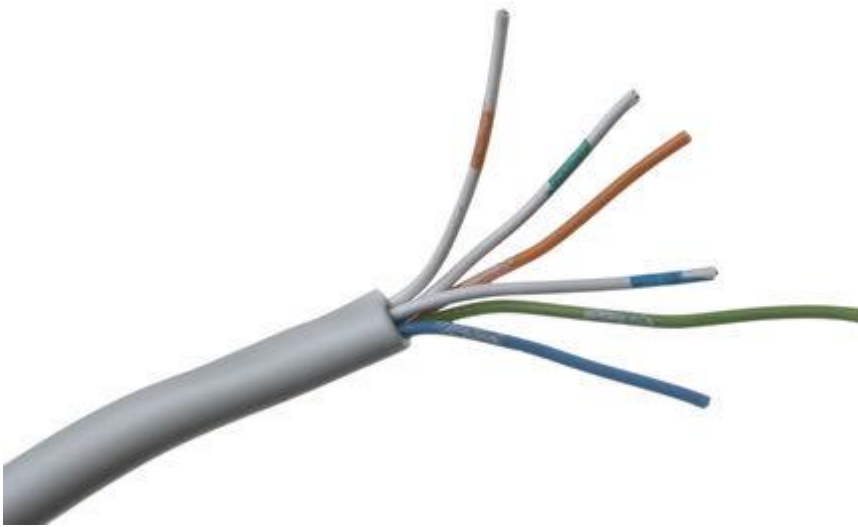

Description:

Rated Temperature (oC): -20 ~ 80

Rated Voltage (V):300



ENGLISH

Construction:

Conductor: Bare Copper

Conductor Dia. (mm): 0.50 ± 0.02

Insulation: SR-PVC

Insulation Dia. (mm): 0.90 ± 0.10

A rip cord: 210 D

Jacket: PVC

Outer Dia. (mm): 4.2 ± 0.1

Colour:

The colour of the insulation: See Table

The jacket colour: White

Marking(3times/m):

RS 5202633 CW 1308 TELECOM 3PR

Mechanical Characteristics:**Test Object:** Insulation**Test Material:** PVC**Tensile Strength (Mpa):** ≥ 12.5 **Elongation (%):** ≥ 125 **Cold Bend (-20 +/- 2 °C x 4Hrs):** No Crack**Heat Shock (80 +/- 2 °C x 2Hrs):** No Crack**Electrical Characteristics:****Max.Conductor DC Resistance at 20°C (Ω /Km) :**

<97.8

Min.Insulation DC Resistance at 20°C ($M\Omega$ *KM) :

>500

