

Datasheet

Stock No: 186-6362

RS Pro Automotive, Surge Protection Tool Kit



Product Details:

Anti-Surge Test Kit

- 16 different types of fuses
- 2 types of fuseholder
- Replacement fuses and fuseholders available separately

Contents

1¼in. 250V LBC Spring	3, 5A
1¼in. 250V LBC Spiral	2, 3, 5A
20mm. 250V LBC Spiral	0.5, 1, 2, 3.15, 5A
20mm. 250V HBC Ceramic	2, 3.15, 5A
1¼in. 440V HBC Ceramic	5, 10A
Panel Mounting Fuseholders	20mm, 1¼in.

Specifications:

Fuse Type: Mains

Kit Includes: (130) Assorted Mains Fuses, (2) Fuse Holder, Fuse Tester




(GB) Anti-Surge Fuse Kit - RS Stock No. 186-6362

(D) Überlastungsschutz-Sicherungs-Sortiment - RS Best Nr. 186-6362

(I) Corredo fusibili anti-sovralimentazione RS codici. 186-6362

(GB) A selection of both 32mm and 6.35mm anti-surge fuses. Time/current characteristics **(D)** Dieses Sortiment enthält 32mm und 6,35mm Sicherungen für Überlastungsschutz. Zeit/Strom-Charakteristik

(I) Una selezione di entrambi i tipi di fusibile, 32mm e 6,35mm anti-sovracorrente.

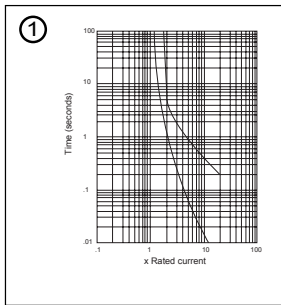


RS 412-611,542-1749

(GB)
32 x 6.35mm applications:
light electronic loads,
telecom, automotive.

(D)
32 x 6,35mm Anwendungen:
Kleine Elektronik-Lasten,
Telekommunikation,
Fahrzeuge.

(I)
32 x 6,35mm applicazioni:
carichi elettronici leggeri,
telecomunicazioni,
costruzioni automobilistiche

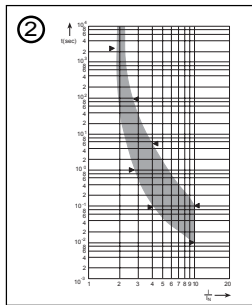


RS 419-791, 419-779, 419-785

(GB)
5 x 20mm applications:
protection of motors and
transformers

(D)
5 x 20mm Anwendungen:
Schutz von Motoren und
Transformatoren.

(I)
5 x 20mm applicazioni:
protezione di motori e
trasformatori.

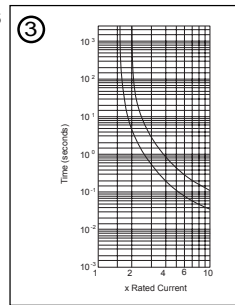


RS 157-9737, 157-9787,157-9709

(GB)
5 x 20mm applications:
light electronic loads, telecom
automotive

(D)
5 x 20mm Anwendungen:
Kleine Elektronik-Lasten,
Telekommunikation,
Kraftfahrzeuge

(I)
5 x 20mm applicazioni:
carichi elettronici leggeri,
telecomunicazioni, costruzioni
automobilistiche

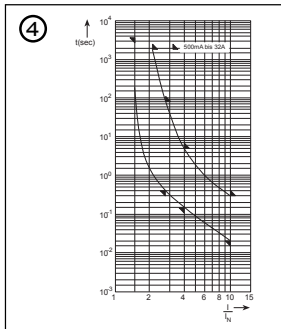


RS 414-061, 414-055

(GB)
32 x 6.35mm applications:
protection of motors and
transformers

(D)
32 x 6,35mm Anwendungen:
Schutz von Motoren und
Transformatoren

(I)
32 x 6,35mm applicazioni:
protezione di motori e
trasformatori

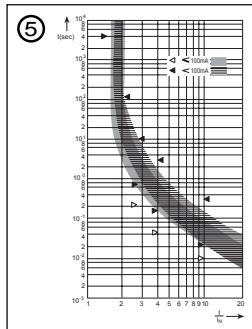


RS 415-597, 415-569, 415-626

(GB)
5 x 20mm applications:
colour TV, VDU, power
supplies transformer loads

(D)
5 x 20mm Anwendungen:
Farbfernseher, Videomonitore,
Stromversorgungen,
Transformator-Lasten

(I)
5 x 20mm applicazioni:
TV a colori, VDU,
alimentazione di potenza,
carichi di trasformatori.

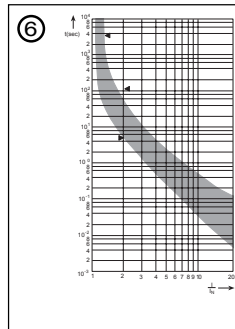

RS 415-733, 415-727, 415-705

(GB)
32 x 6.35 applications:
colour TV, VDU, automotive,
transformer loads

(D)
32 x 6,35mm Anwendungen:
Farbfernseher, Videomonitore,
Kraftfahrzeuge, Transformator-
Lasten

(I)
32 x 6,35mm applicazioni:
TV a colori, VDU, costruzioni
automobilistiche, carichi di
trasformatori.

(GB) Please refer to the current RS catalogue for further information or contact the RS Technical Helpline

(D) Weitere Information entnehmen Sie bitte dem RS-Katalog oder kontaktieren Sie die Technische Hilfe von RS

(I) Per ulteriori informazioni, si prega di consultare il catalogo RS corrente oppure di contattare il Supporto Tecnico RS in linea.

32mm (T) spring type Feder-Typ Tipo a molla 5A 250V ~ RS 412-611	20mm (T) spiral wound spirale A spirale 1A 250V ~ RS 537-1379	20mm (T) 2A HBC 250V ~ RS 563-609	32mm (T) 10A HBC 440V ~ RS 414-061	20mm (T) spiral wound spirale A spirale 2A 250V ~ RS 541-2953	32mm (T) spiral wound spirale A spirale 5A 250V ~ RS 541-3041
32mm (T) spring type Feder Typ Tipo a molla 3A 250V ~ RS 668-6082	20mm (T) spiral wound spirale A spirale 3.15A 250V ~ RS 537-1335	20mm (T) 3.15A HBC 250V ~ RS 563-699	32mm (T) 5A 440V ~ RS 414-055	20mm (T) spiral wound spirale A Spirale 1A 250V ~ RS 541-2931	32mm (T) spiral wound spirale A spirale 3A 250V ~ RS541-3035
20mm (T) 5A HBC 250V ~ RS 563-693	20mm (T) spiral wound spirale A spirale 500mA 250V ~ RS 537-1385	20mm panel mounting fuseholder Sicherungs-Halter, Einbau Portafusibili per montaggio su pannello RS 359-3375	32mm 10A panel mounting- fuseholder Sicherungs-Halter, Einbau Portafusibili per montaggio su pannello RS 412-863	20mm (T) spiral wound spirale A spirale 5A 250V ~ RS 541-2981	32mm (T) spiral wound spirale A spirale 2A 250V ~ RS 541-3029