


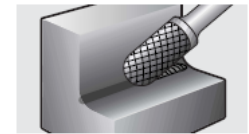

ball nosed cylinder

Walzenrundform
cylindrique bout rond
cilindro esférico



	d1 mm	l1 mm	d2 mm	l2 mm	s	d	d-max	c	k	alu	I.S.O. Ref.	SCTI Nr.
	2.5	11	3	38	T3100	T3100D	-	-	-	-	-	SC-41M
	3	13	3	38	T3200	T3200D	-	T3200C	T3200K	-	C031303	SC-42M
	3	13	3	50	-	T3200DL	-	-	-	-	C031303	SC-42ML2
	3	13	3	75	-	T3200DXL	-	-	-	-	C031303	SC-42ML3
	4	16	6	50	T3300-6	T3300D-6	-	-	T3300K-6	-	C041606	SC-13M
	5	16	6	50	-	T3350D-6	-	-	-	-	C051606	SC-14M
	6	13	3	45	T3240	T3240D	-	-	-	-	C061303	SC-51M
	6	19	6	50	T3400	T3400D	-	T3400C	T3400K	-	C061906	SC-1M
	6	25	6	50	-	T3400D-1	-	-	-	-	C062506	SC-1ML
	8	19	6	65	T3500	T3500D	-	-	T3500K	-	C081906	SC-2M
	10	19	6	65	T3600	T3600D	-	-	T3600K	-	C101906	SC-3M
					-	TDX350	-	-	-	-	-	-
					-	TDX360	-	-	-	-	-	-
					-	TTA340	-	-	-	-	-	-