



- Clear domes ensure signalling effect even in direct sunlight
- Plastic housing with aesthetic metal coating
- LED Permanent light elements with life duration up to 50,000 hours
- Simplified ordering through ready-assembled tower
- 36 mm diameter
- Can be operated with PLC control system
- Available with user-friendly plug connection

TECHNICAL SPECIFICATIONS:

Dimensions (Diameter x Height): 2 tier: 36 x 113 mm

3 tier: 36 x 147 mm

Housing: Housing parts PC

Fixing: Base mounting

Tube mounting

Bracket mounting

Connection: cable, 2 m long,

M12 plug,

each with adapter M25 / M20 for

fixing rubber seal

Operating voltage: 24 V DC

Current consumption: 40 mA per tier

Starting current: < 500 mA can be triggered via PLC


ORDER SPECIFICATIONS:

		Order no.	Connection type
2 tier	red/green	693 080 55	cable
	red/yellow	693 090 55	cable
	red/green	693 580 55	plug-type
	red/yellow	693 590 55	plug-type
3 tier	red/yellow/green	693 070 55	cable
	red/yellow/green	693 570 55	plug

Available from June 2005

ACCESSORIES:

Fixing bracket, black	960 693 01
Cable gland M20 x 1.5	960 693 02
Base with integrated tube M25 x 1.5	960 693 06
including rubber seals, silver	
M12 counter-plug with 5m cable	960 693 05

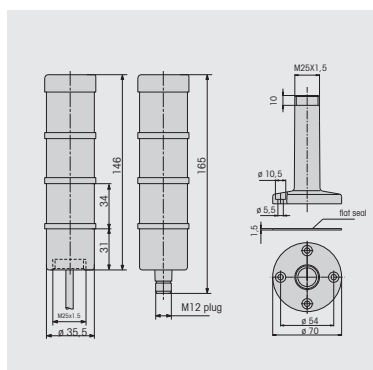

2 tier

3 tier

