

Verbatim LED Mini Globe E27 5.5W 2700K Warm White 330 LM


- E27 Socket
- 220 - 240V Voltage
- 15,000 hours Lifetime
- 82% Energy Saving
- Lumen: 330
- Equivalent to 30W incandescent bulb

Product Number	52606
General Data	
Lamp Socket	E27
Electric Data	
Wattage (W)	5.5
Wattage Equivalent (W)	30
Voltage (V)	220 - 240V
Dimmable	no
Power Factor	0.50
Operating Frequency (Hz)	50-60
Geometric Data	
Length (mm)	74.5
Diameter (in mm)	45
Weight (g)	59.5
Photometric Data	
Luminous Flux (lm)	330
CRI	80
CCT (K)	2700
Beam Angle (°)	160
Luminous Efficacy (lm/W)	60
Lifetime (hrs)	15,000
Switching Cycle	20,000




02/07/2014

Photometric Diagrams

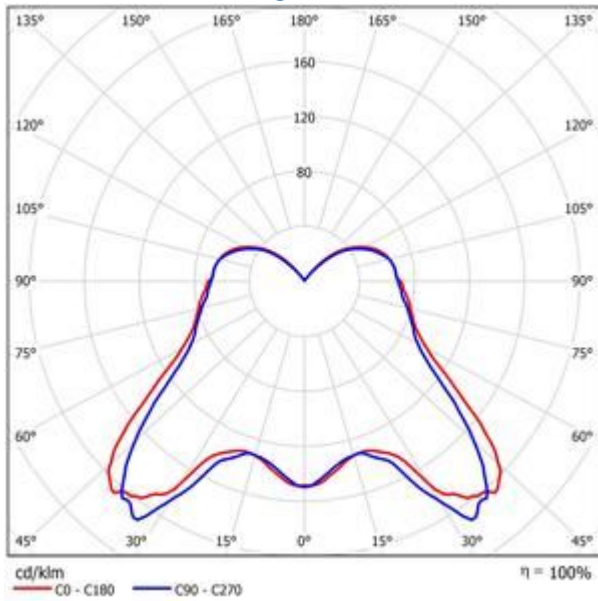

Energy Rating

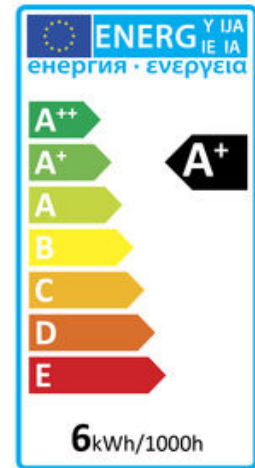

Technical Packaging Details

Barcode

023942526063

EAN 128

(02)00023942526063(37)04(91)204

EAN 14

50023942526068

Pack Dimensions(HxWxL)

145 x 103 x 51

Pack Weight

93

MOQ

4

Carton Dimensions (HxWxL)

160 x 117 x 223

Cartons/Pallet

150

Layers/Pallet

5

Units/Pallet

600

02/07/2014