

## Datasheet

### Nylon 6 Flexible Conduit, 25mm 10m

RS Stock number [755-9001](#)



#### Description:

##### Nylon Flexible Conduit


Nylon conduit ideal for running cable protection in Electrical/Machinery/Building Harness wiring

Flexible body facilitates corner/elbow wiring

Close design

#### Specifications:

Conduit Type:	Flexible
Colour:	Black
Interior Diameter:	23mm
Length:	10m
Material:	Nylon 6
Nominal Diameter:	25mm
Outer Diameter:	28.5mm

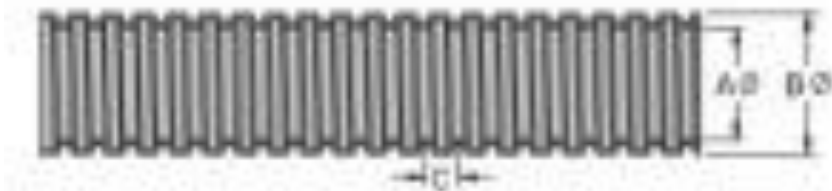

Unit : mm

RS Item No.	Inch	Aφ	Bφ	C	Packing
7559004	3/8"	12.2±0.4	15.8±0.4	2.1	25 M / Roll / Bag
7559007	1/2"	16.8±0.4	21.7±0.4	2.3	25 M / Roll / Bag
7559001	3/4"	23.0±0.4	28.5±0.4	2.3	10 M / Roll / Bag
7559010	1"	28.6±0.4	34.4±0.4	2.5	10 M / Roll / Bag