




<b>Material</b>	Fiberglass re-inforced Polypropylene and TPE - Halogen Free UL approved materials
<b>Mode of protection</b>	IP65
<b>Temperature range</b>	-20°C....+125°C <sup>(1)</sup>
<b>Test standard</b>	EN 60529:1991 + A1 EN 60670-1:2005, EN 50262:1998 EMKO-TUI(03-SEC)FI001/84
<b>Semko report</b>	816003

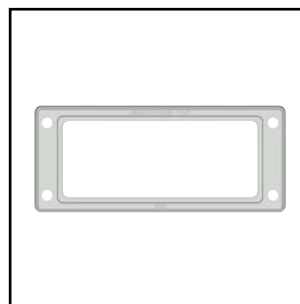


E-26 654 00 / 18

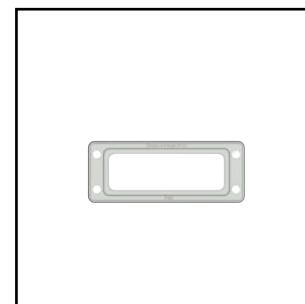


E-26 654 04 / 22

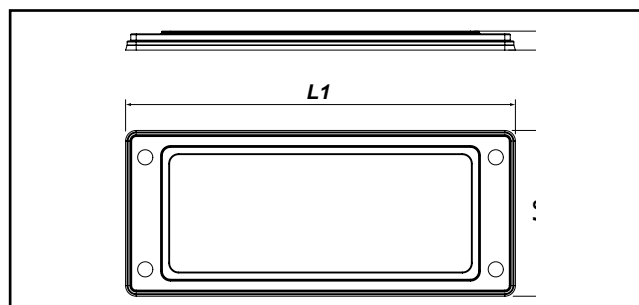


E-number	Size	L1 mm	L2 mm	H mm	Pcs pack	
<b>RAL 7035</b>						
T_26 654 00	FL21	214	90	9	10	100
T_26 654 04	FL13	134	52	6,5	10	100
<b>RAL 9005</b>						
T_26 654 18	FL21	214	90	9	10	100
T_26 654 22	FL13	134	52	6,5	10	100
<b>RAL XYZ</b>						
FL21 FRAME XYZ	FL21	214	90	9	10	100
FL13 FRAME XYZ	FL13	134	52	6,5	10	100

## Standards and measurements

### FL 13

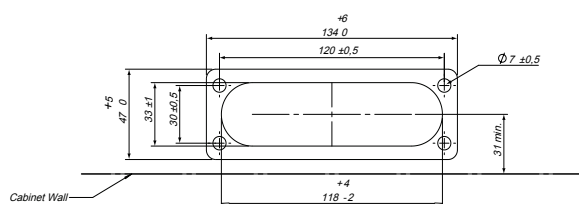

### FL 21

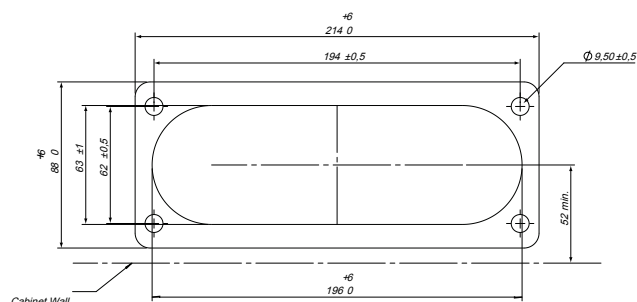

(1) Unstressed material.