

PB pushbutton box



Stainless steel pushbutton boxes:

These UL Type boxes are designed to house pushbuttons, selector switches, pilot lights, and help protect such equipment against dirt, dust, water, oil or coolant.

- Accepts 22.5 and 30.5 mm devices
- Available in sizes from a single position to 42 hole positions

Rugged And versatile:

The standard holes accept all brands of 22.5 and 30.5 mm, 4-way, oil-tight pushbuttons, switches and pilot lights. Several of these enclosures can be mounted onto a Rittal column and base for use as an operator station. Additionally, external mounting brackets and captive, stainless steel cover screws make installation quick and easy.


Technical specifications:

- Enclosures and covers are made from 14-gauge Type 304 stainless steel
- Interior and exterior surfaces have a #4 brushed finish

Protection rating:

UL Type 12, 13, 4 & 4X
UL/cUL
UL file #: E118617

Standard 4-Way Keyed Pushbutton Hole Detail:

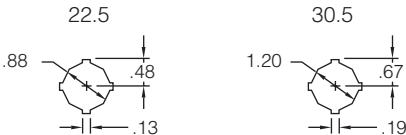

Hole Arrangement Centered On Cover

Type 304 Stainless Steel – Standard		
Hole Size 30.5 mm		
Description		Part No.
1 Hole		PB01305S14
2 Hole		PB02305S14
3 Hole		PB03305S14
4 Hole		PB04305S14
4 Hole		PB04305S24
5 Hole		PB05305S14
6 Hole		PB06305S24
9 Hole		PB09305S34
12 Hole		PB12305S34

Note: To order PB boxes in Type 316L stainless steel replace the ending 4 with a 6 (extended delivery times).

Type 304 Stainless Steel – Slim/Miniature	
Hole Size 22.5/30.5 mm – all in single column	
Description	Part No.
1 Hole	PB01305L14
1 Hole	PB01225M14
2 Hole	PB02305L14
2 Hole	PB02225M14
3 Hole	PB03225M14
4 Hole	PB04225M14
6 Hole	PB06225M24
9 Hole	PB09225M34
12 Hole	PB12225M34

Note: To order PB boxes in stainless steel Type 316L replace the ending 4 with a 6 (extended delivery times).

Type 304 Stainless Steel – Extra Deep, 4.75" depth	
Hole Size 30.5 mm	
Description	Part No.
1 Hole	PB01305X14
2 Hole	PB02305X14
3 Hole	PB03305X14
4 Hole	PB04305X14
4 Hole	PB04305X24
6 Hole	PB06305X24
9 Hole	PB09305X34
10 Hole	PB10305X24
12 Hole	PB12305X34
16 Hole	PB16305X44
16 Hole	PB16305X24
20 Hole	PB20305X44
25 Hole	PB25305X54

Note: To order PB boxes in Type 316L stainless steel replace the ending 4 with a 6 (extended delivery times).

