

## Protective covers - HC-B 24-SD-FQ/FS - 1772609


Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)



HEAVYCON protective cover, series B24, for supporting base element with double locking latch, with retaining cord, IP54, PA



### Key commercial data

Packing unit	10 pc
GTIN	 4 017918 037277
Weight per Piece (excluding packing)	39.95 g
Custom tariff number	85389099
Country of origin	Germany

### Technical data

#### Dimensions

Diameter of retaining cord eyelet	30 mm
-----------------------------------	-------

#### Ambient conditions

Degree of protection	IP54
Ambient temperature (operation)	-20 °C ... 100 °C

#### General

Type	B24
	For supporting base element with double locking latch
Inflammability class according to UL 94	HB
Seal present	No
Assembly instructions	Not for HC-B...EMC housings
Connection	Plastic protective cover for short-term protection

### Classifications

#### eCl@ss

eCl@ss 4.0	27140816
------------	----------

# Protective covers - HC-B 24-SD-FQ/FS - 1772609

## Classifications

### eCl@ss

eCl@ss 4.1	27140816
eCl@ss 5.0	27142104
eCl@ss 5.1	27142104
eCl@ss 6.0	27142104
eCl@ss 7.0	27142104
eCl@ss 8.0	27142104

### ETIM

ETIM 2.0	EC000437
ETIM 3.0	EC000437
ETIM 4.0	EC000437
ETIM 5.0	EC000437

### UNSPSC

UNSPSC 6.01	30212113
UNSPSC 7.0901	39121712
UNSPSC 11	39121712
UNSPSC 12.01	39121712
UNSPSC 13.2	39121712

## Approvals

### Approvals

---

Approvals

GOST

---

Ex Approvals

---

Approvals submitted

---


### Approval details

GOST 
--

## Drawings

## Protective covers - HC-B 24-SD-FQ/FS - 1772609

Dimensioned drawing

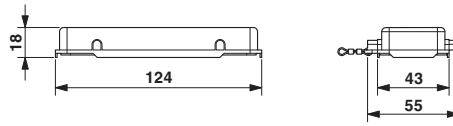

Protective cover, B24