

ATPH 1850-0200



Alu-Topline
 Enclosure profiles, horizontally-divided

Order no.: 92850200

Colour of enclosure group

Natural-coloured anodised aluminium profile; plastic lid quartz grey, similar to RAL 7039 or graphite grey, similar to RAL 7024; special colours on request

Protection class


IP 40/DIN EN 60529; IP 54/DIN EN 60529 as an option

Enclosure material

Extruded profiles: Al Mg Si 0.5 anodised; plastic lid: ABS; for details see Technical Information

Scope of delivery: Enclosure profile, 2 parts

Note: Special lengths on request.

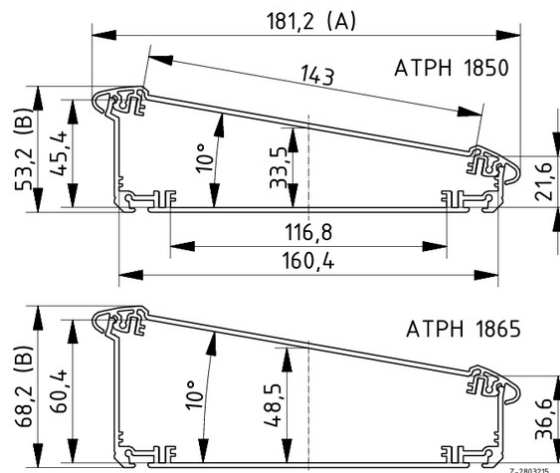

A	181,2 mm
B	53,2 mm
C	200 mm

Technical drawings

3D product data in STEP format:

[Registration necessary](#)

Catalogue drawing in DXF format:

[92850200_ATPH-1850-0200.dxf](#) (490 KB)

Basic drawing for processing work:

[92850200_ATPH-1850-0200-G.dxf](#) (422 KB)

Catalogue drawing in PDF format:

[92850200_ATPH-1850-0200.pdf](#) (42 KB)

Assembly instructions

[Alu-Topline-AT-0...-7024-UWB.pdf](#) (500 KB)

Chapter download

[Alu-Topline_GB.pdf](#) (326 KB)


Accessories



End cover

92050024 [ATD 1850-7024](#)
92050039 [ATD 1850-7039](#)

For ATPH 1850 Graphite grey
For ATPH 1850 Quartz grey

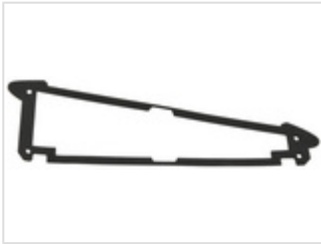

Seals for ingress protection IP 54

92050000 [AT 1850 DI](#)

For ATPH 1850



Wall fastening, aluminium

92800200 [AT 1800-0200 WB](#)

For ATPH-0200



Universal wall fitting

92820024 [AT 0200-7024 UWB](#)

For ATPH-0200 Graphite grey



Insulating strip for PCB mounting on the profile

92000100 [AT-IS 00020](#)

Length: 101,5 mm



Rubber feet

84006700 [AB - GF](#)

Polyurethane, 65-75 Shore Black

* = Available on request