


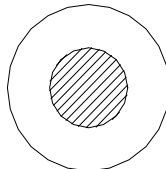

Product Name:	UL1180 26AWG
Product Discription:	UL1180 26AWG
Specification No.:	
Customer's Name:	

Description					Construction								
Rated Voltage:		300Vac(UL allows 600V for electronic use only).			Conductor		Stranded Sliver plated copper						
Rated Temperature:		200℃,Optional - 80 ℃ Oil, Gasoline Resistant.			Size(AWG)		26						
Reference Standard:		UL758			Construction(±0.008mm)		7/0.16						
Cross Section					Stranded Dia.(mm)Ref.		0.48						
					Insulation Material		PTFE						
					Insulation Color		ANY COLOR						
					Ave Thickness(mm)		0.33						
					Insulation Dia.(±0.08mm)		1.22						
Marking					Remark:								
No marking on the cable jacket, have UL label on the Reel.					8740172 Red		8740175 Blue		8740194 Grey		8740197 Violet		
					8740169 Black		8740179 White		8740181 Yellow				
					8740163 Brown		8740188 Green		8740185 Orange				
Applications					Characteristics						Customer Approve		
For internal wiring of electronic and electrical equipment					Test Item				Standard Value				Seal & Stamp
					Test Material				PTFE(ROHS)				
					Insulation resistance(20℃ MΩ*m				1000				
					Vol. Tesr(AC.V.60S) (V)				2000				
					Flammability Test				Horizontal flame				
Revisions					Max.DC Resistance(20℃ Ω/km)				127(MAX)				Signature: Date:
Version	Description		Drawn by	Approved by	Date								
0	New document issue		Danniel	Jason	24/04/2015								