

This is a sample photo.

ORDER SYMBOL: FEX 2828 13 G

EL.number **EAN:** 6418074007995

Sweden:
Denmark: 8212026382
Finland: 3424657

INCLUDING:
Enclosure body, cover, 4 slotted cover screws, and mounting screws.



APPROVALS:

USA: NEMA 1, 4X, 6, 12, 13; UL 94-V0; KEMA: Ex-97.D.3891 U

EURO: IP 67; UL 94-V0; KEMA: Ex-97.D.3891 U

OTHERS: IEC 529, KEMA Ex-97.D.3891 U, GL 07.09-92, FIMKO 197843-01, LR 90/00197 (E4)

FIBOX FEX-PC-7

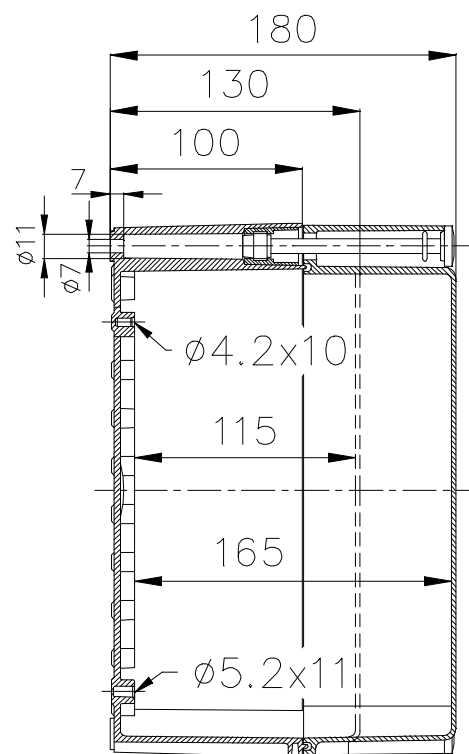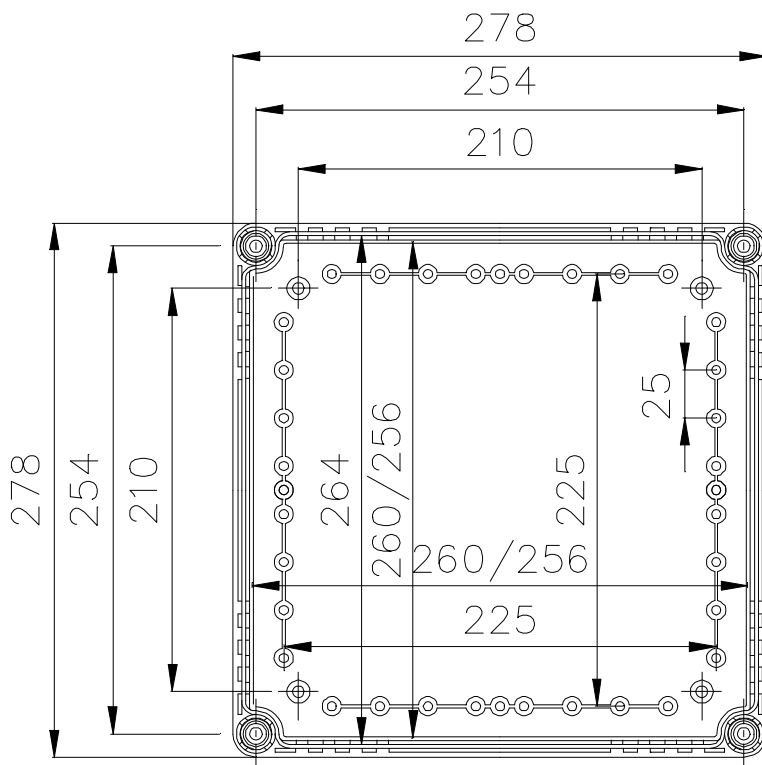

TECHNICAL INFORMATION:

Standard colour: RAL 7035	Temp.range in cont. use: Max. +80 °C
Ingress protection: IP 67 (IEC 529)	Temp. range of material: - 40 °C - + 120 °C
Flame resistance:	

ACCESSORIES

Extension frame	EKJZR	DIN-Rail	EKV 24
Extension frame	EKMZR	DIN-Rail	EKV 32
Extension frame	EKOZR	DIN-Rail	EKV 34
Extension frame	EKPZR	Corner plug	MB 10523
Extension frame	EKTZR	Fastening lug	MB 10674
Extension frame	EKUZR	Earth bar support	MB 26069
DIN-Rail	EKV 12	Earth bar set	MR 26059
DIN-Rail	EKV 14		
DIN-Rail	EKV 22		