

Model **DEB** LED Lamp

## Recommended Product

For more details on Model DEB  
Refer to the "Replacement Bulb"  
Section at the end of this Catalog



# RH-A/ RK-A

## Revolving Warning Light


**Bulb**
**IP55** (with SZ-200A)

**1**
**Alarm Sound** (RHB & RKB)

**90dB** at 1m (RHB & RKB)

**Terminal**
**Ø100**


Optional Rubber  
Gasket SZ-200A

## Compact Revolving Warning Light featuring high durability and easy wiring with terminal block.

### FEATURES

- Indoors allows upright, inverted, and sideways installation; Outdoors allows upright installation only.
- Has the CE mark and conforms to the requirements (for 12V, 24V type only) for the EC directive.
- Dome is made from superior impact and heat resistant polycarbonate resin.
- Main body is made of impact and heat-resistant polycarbonate resin.
- Built-in audible alarm for models RHB/RKB at a sound of 90dB (at 1m).
- Rotating parabolic reflector to enhance visibility from a distance.
- Is UL Listed for 24V, 120V, and 240V types (File No. E215660)
- Vibration-resistant automobile bulb for extended bulb life.
- Available Colors are Red, Amber, Green, and Blue.
- Utilizes a terminal block for easy wiring.


AVAILABLE BY SPECIAL ORDER (RH TYPE)

- Body Color: Silver


### How to Order

| Model | Rated Voltage | Color    | Conformity           |
|-------|---------------|----------|----------------------|
| RK-A  | 12 : DC 12V   | R: Red   | None : Standard      |
| RH-A  | 24 : DC 24V   | Y: Amber | (UL) : UL Conformity |
|       | 100: AC 100V  | G: Green |                      |
|       | 200: AC 200V  | B: Blue  |                      |

### Dimensions

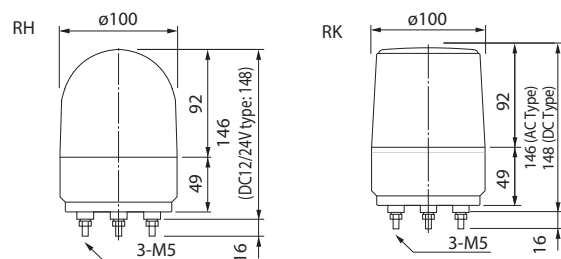

### Mounting Dimensions

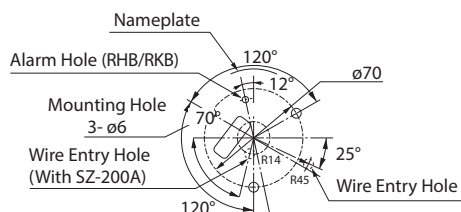

(Unit: mm)

### Specifications

| Model            | Rated Voltage | Current Consumption | Flash Rate (fpm) | Bulb    |           | Mass |
|------------------|---------------|---------------------|------------------|---------|-----------|------|
|                  |               |                     |                  | Ratings | Repl. No. |      |
| RH/RHB-12A       | DC 12V        | 0.8A                | 170              | 12V 10W | 9         | 400g |
| RH/RHB-24A (UL)  | DC 24V        | 0.5A                |                  | 24V 10W | 10        |      |
| RH/RHB-120A (UL) | AC 120V       | 0.1A                |                  | 12V 5W  | 12        | 600g |
| RH/RHB-200A      | AC 200V       | 0.03A               |                  | 24V 10W | 10        |      |
| RH/RHB-240A (UL) | AC 240V       | 0.05A               |                  | 12V 5W  | 12        | 600g |
| RK/RKB-24A (UL)  | DC 24V        | 0.5A                |                  |         |           |      |
| RK/RKB-120A (UL) | AC 120V       | 0.1A                |                  |         |           |      |
| RK/RKB-200A      | AC 200V       | 0.03A               |                  |         |           |      |
| RK/RKB-240A (UL) | AC 240V       | 0.05A               |                  |         |           |      |