


Datasheet

2.7mm Pitch 25 Way IDC D-sub Connector, Socket, Metal Shell

RS Stock number [642-4913](#)

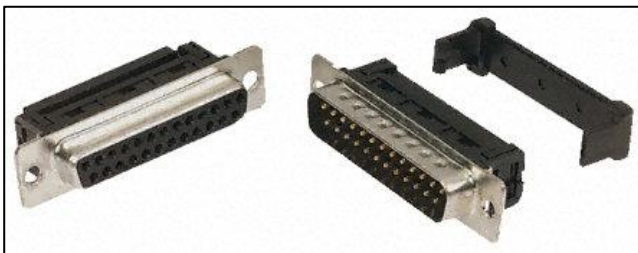

Description:

Low Profile Metal Body
0.8 μ m selective gold plated pins

Specification:

Body Orientation: Straight
Contact Plating: Gold
Current Rating: 1A
Gender: Female
Housing Material: Metal
Maximum Operating Temperature: +85°C
Minimum Operating Temperature: -55°C
Number of Contacts: 25
Pitch: 2.77mm

Dimensions:

