

# EM 212



Euromas II  
Enclosure, polycarbonate

Order no.: 62212000

Colour of enclosure group

Light grey, similar to RAL 7035; special colours on request


Protection class

IP 65/DIN EN 60529; higher ingress protection on request

Enclosure material

ABS, PC (UV stabilised); seal made of CR; UL 94 V0 types on request; for details see Technical Information

Scope of delivery: Lid and base, self-tapping coarse-pitch thread lid screws made of V2A

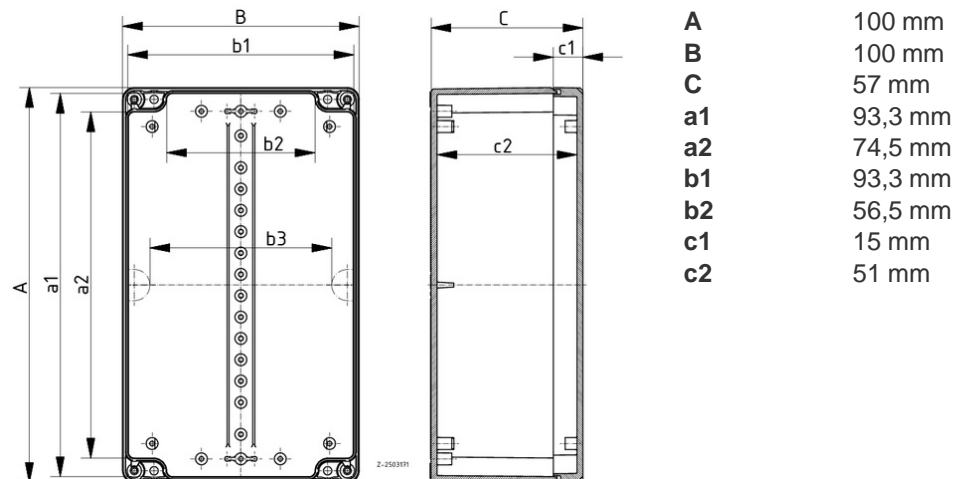

Technical drawings

Catalogue drawing in DXF format:

[62212000\\_EM-212.dxf](#) (788 KB)

3D product data in STEP format:

[Registration necessary](#)

Basic drawing for processing work:

[62212000\\_EM-212-G.dxf](#) (445 KB)

Catalogue drawing in PDF format:

[62212000\\_EM-212.pdf](#) (81 KB)

Chapter download

[Euromas II\\_GB.pdf](#) (362 KB)

## Accessories



### Rubber feet, self-adhesive

22009000

[GF](#)

Polyurethane, 65-75 Shore Black



### Wall brackets, screw-on at rear

22010000

[EM-WL](#)



### Screw covers

22080000

[EM-SA](#)



### Mounting panels, laminated paper

22212000

[M](#)

For EM/ET 212\*\*



### DIN rail acc. to DIN EN 60715 TH 15

22150901

[TS 15](#)

For EM/ET 212



### DIN rail acc. to DIN EN 60715 G 32

22320901

[TS 32](#)

For EM/ET 212



### DIN rail acc. to DIN EN 60715 TH 35

22350901

[TS 35](#)

For EM/ET 212



\* = Available on request